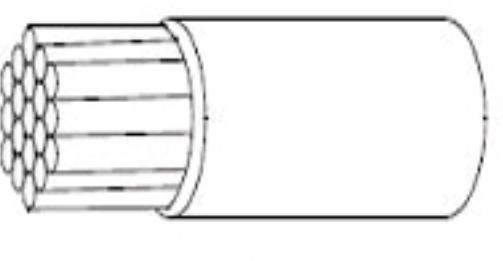


22759/44-20-1 Product Details

[!\[\]\(e3f8612927870f2e0f9f5989e6dd3064_img.jpg\) Share](#) [!\[\]\(a86c7d1c9cb81c81614634a31267440d_img.jpg\) Print](#) [!\[\]\(ce158fc5e55633398941d0898ae45661_img.jpg\) Email](#)

Spec 44, Spec 55 and Spec RCW Wire and Cable

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

22759/44-20-1

TE Internal Number: 080929-000

[View all Features](#)[!\[\]\(4f6bf54ae7e4144a72d78316053e412d_img.jpg\) Add to My Part List](#) [!\[\]\(1be454ab98bc856a53cc962da77a541d_img.jpg\) Request Sample](#) [!\[\]\(c0149066729715e1f65b56e37efafeee_img.jpg\) Find Similar Products](#) [!\[\]\(44211123bbd9216afa358c226e756ccd_img.jpg\) Buy Product](#)**Quick Links**

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information**Product Drawings:**

- [Wire, Radiation-Crosslinked, Modified ETFE-Insulated...](#) (PDF, English)

Related Products:

- [Tooling](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

[List all Documents](#)**Product Features** (Please use the Product Drawing for all design activity)**Product Type Features:**

- [Cable Type](#) = Spec 55
- [Cable Style](#) = Primary
- Number of Conductors = 1

Conditions for Usage:

- Temperature Range (°C) = -65 - +200
- Wire Size - Details = 20 AWG 0.62 mm², 0.00095 in², 19 x 32 AWG

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Operation/Application:

- Application = General Purpose - Lightweight

Body Features:

- Wire Size (AWG/CM) = 20 AWG
- Conductor Type = Silver-Plated Copper
- Wire Color = Brown
- Nominal Outside Diameter (mm [in]) = 1.27 [0.050]
- Wire Diameter (mm [in]) = 1.27 [0.050]
- Conductor O.D. (mm [in]) = 1.01 [0.040]

Packaging Features:

- Wire Source = United States

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M22759/44-20-1
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = Raychem

Corporate Information[Who We Are](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)**Quick Links**[Check Distributor Inventory](#)[Cross Reference](#)[Find Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)**Customer Support**[Email or Chat With Us](#)[Find a Phone Number](#)[Search Knowledge Base](#)[Manage your Account](#)**Keep Me Informed**

Receive TE News, Events & Technology Updates

Enter your email address 