


## Data Sheet | Item Number: 770-523

Shield connecting plate; 3-pole; for sockets and plugs; silver-colored

<https://www.wago.com/770-523>

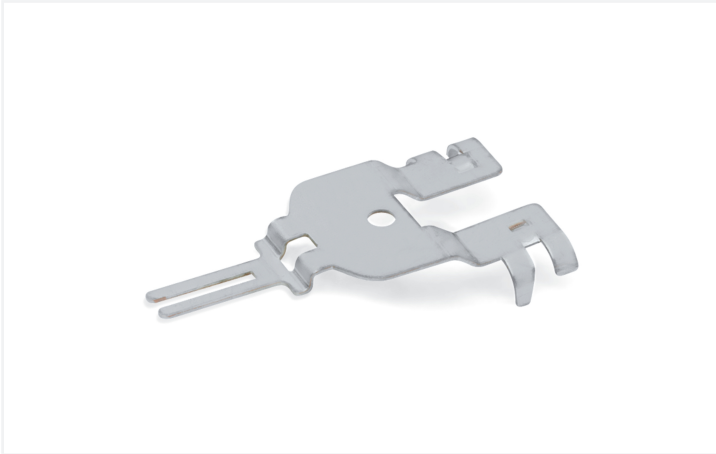

Color: ■ silver-colored

### Shield termination *WINSTA*® MIDI 3-pole

When using the shield termination from the *WINSTA*® MIDI product line, zero-defect installation is guaranteed. An extensive range of accessories complements the *WINSTA*® product line from WAGO. *WINSTA*® MIDI with Push-in CAGE CLAMP® spring pressure connection technology is used in can be found in a variety of projects you can use for quick, easy, flexible, and secure installation.

Lower costs through fast commissioning and elimination of service expenses – solutions from *WINSTA*® MIDI

The *WINSTA*® Pluggable Connection System is perfectly tailored to the strict requirements of building installation. It makes electrical installation pluggable, and thus more efficient, more reliable, and error-free. Use of this pre-assembled system reduces time spent on assembly and installation errors at the construction site. Take advantage of the pluggable version of our maintenance-free spring pressure connection technology too! Plan your installation with with protection against mismatching from WAGO.

- pre-assembled versions
- quick replacement of defective units during ongoing operation

## Notes

General safety information

### **NOTICE: Observe installation and safety instructions!**

1. Only to be used by a qualified electrician or by a person electrically instructed for the task (EIP per DIN VDE 0105-100).
2. Do not install while energized or under load.
3. Use only for its intended purpose.
4. Observe applicable national regulations, standards and directives.
5. Observe the technical specifications of the products.
6. Ensure correct polarity assignment.
7. Do not use damaged or contaminated components.
8. Observe conductor types, conductor cross-sections, strip lengths and cable diameters.
9. Insert conductors up to the stop.
10. Use only with locking lever and strain relief.
11. Use original accessories only.

**To be sold only with installation instructions!**

## Connection Data

### Connection 1

Pole number	3
-------------	---

## Physical data

Width	25.6 mm / 1.004 inches
Height	6.95 mm / 0.274 inches
Depth	44.8 mm / 1.764 inches

## Mechanical data

Suitable	for socket and plug
----------	---------------------

## Material data

Note (material data)	<a href="#">Information on material specifications can be found here</a>
Color	silver-colored
Flammability class per UL94	V0
Weight	2.4 g
Material	Copper (SE Cu); special tin coating

## Environmental requirements

Processing temperature	-5 ... +40 °C
Continuous operating temperature	-35 ... +85 °C
Note on continuous operating temperature	Insulating parts for temperatures ≤ 105 °C

## Commercial data

Product Group	20 (Winsta)
PU (SPU)	50 pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454662684
Customs tariff number	85366990990

## Product Classification

UNSPSC	39121421
eCl@ss 10.0	27-44-06-92
eCl@ss 9.0	27-44-06-92
ETIM 9.0	EC002863
ETIM 10.0	EC002863
ECCN	NO US CLASSIFICATION

### Environmental Product Compliance

RoHS Compliance Status

Compliant, No Exemption

### Downloads

#### Environmental Product Compliance

##### Compliance Search

Environmental Product  
Compliance 770-523



### Documentation

#### Bid Text

770-523	19.02.2019	xml 2.60 KB	
770-523	11.03.2015	doc 21.50 KB	

### CAD/CAE-Data

#### CAD data

2D/3D Models 770-523



#### CAE data

WSCAD Universe  
770-523

