

UCT-WMCO 4,1 (18X4) - Wire marking



0830785

<https://www.phoenixcontact.com/us/products/0830785>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Wire marking, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: clip on, cable diameter range: 3.5 ... 4.1 mm, lettering field size: 18 x 4 mm, Number of individual labels: 32

Your advantages

- The UCT-WMCO ... UniCard labeling range includes markers for the subsequent labeling of conductors by simply snapping on
- Large-surface labeling option in a space-saving design
- Marking service: Phoenix Contact can custom-mark all UniCard markers according to your specifications
- Secure tight fit even in the event of vibrations
- The format automatically ensures printing with a high degree of positioning accuracy

Commercial data

Item number	0830785
Packing unit	6 pc
Minimum order quantity	6 pc
Sales key	BG10
Product key	BG2218
Catalog page	Page 209 (C-3-2019)
GTIN	4046356772419
Weight per piece (including packing)	14.27 g
Weight per piece (excluding packing)	14.27 g
Customs tariff number	39269097
Country of origin	PL

UCT-WMCO 4,1 (18X4) - Wire marking



0830785

<https://www.phoenixcontact.com/us/products/0830785>

Technical data

Product properties

Product type	Conductor marking
Type	Card form

Marking

Number of individual labels	32
Number of individual labels per row	8

Dimensions

Width	4 mm
Text field width	18.00 mm
Text field height	4.00 mm
Length	18 mm

External dimensions

Outside diameter	3.5 mm ... 4.1 mm
------------------	-------------------

Material specifications

RoHS compliant	yes
Color	white
Material	PC
Flammability rating according to UL 94	V0
Relative insulation material temperature index (Elec., UL 746 B)	130 °C
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R24	HL 1 - HL 3
Components	free from silicone, halogen, and cadmium

Cable/line

External cable diameter	3.5 mm ... 4.1 mm
-------------------------	-------------------

Environmental and real-life conditions

Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

UV resistance

Specification	ISO 4892-2:2013-03 (following)
Result	Test passed
Test duration	96 h

Wipe resistance of inscriptions

Specification	DIN EN 61010-1 (VDE 0411-1):2011-07
	DIN EN 62208 (VDE 0660-511):2012-06 (in parts)

UCT-WMCO 4,1 (18X4) - Wire marking



0830785

<https://www.phoenixcontact.com/us/products/0830785>

Isopropyl [CAS No. 67-63-0]	Test passed
n-Hexane [CAS No. 110-54-3]	Test passed
Water + Petroleum ether [CAS No. 64742-82-1]	Test passed

Testing in a condensation changing climate in the presence of sulfur dioxide

Specification	DIN 50018:2013-05
Result	Test passed
Climate level	AHT 1.0 S
Cycles	2

Salt spray test

Specification	DIN EN 60068-2-11:2000-02
Result	Test passed

Ambient conditions

Ambient temperature (operation)	-40 °C ... 120 °C
Recommended storage conditions	23 °C/50 % relative humidity. Storage in a dry and dark place in the original packaging is recommended.
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %

Standards and regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

Mounting

Mounting type	clip on
---------------	---------

UCT-WMCO 4,1 (18X4) - Wire marking



0830785

<https://www.phoenixcontact.com/us/products/0830785>

Classifications

ECLASS

ECLASS-11.0	27281102
ECLASS-12.0	27281102
ECLASS-13.0	27281102

ETIM

ETIM 9.0	EC001530
----------	----------

UNSPSC

UNSPSC 21.0	39131500
-------------	----------

UCT-WMCO 4,1 (18X4) - Wire marking



0830785

<https://www.phoenixcontact.com/us/products/0830785>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



Accessories

THERMOMARK CARD 2.0 - Thermal transfer printer

1085267

<https://www.phoenixcontact.com/us/products/1085267>



Thermal transfer printer for card materials, including Euro/US power cable and USB cable. User manual printed in German and English. Magazine for UCT-TM.. sheets and magazines for US-... cards. One packing unit each UCT-TM 6, US-EMLP (85,6x54), ink ribbon = 50 m

THERMOMARK PRIME 2.0 US - Thermal transfer printer

1472410

<https://www.phoenixcontact.com/us/products/1472410>



Thermal transfer printer for printing card materials with a print resolution of 300 dpi. Suitable for stationary as well as mobile use thanks a 7" color touch display with integrated "MARKING system app" and a replaceable battery pack.

UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



BLUEMARK ID - Printer

1003334

<https://www.phoenixcontact.com/us/products/1003334>



BLUEMARK ID COLOR - Printer

1002329

<https://www.phoenixcontact.com/us/products/1002329>



UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



TOPMARK NEO - Laser marker

1012015

<https://www.phoenixcontact.com/us/products/1012015>



Laser marking system for the efficient marking of metal or plastic marking material from the LS..., UCT..., UC.../PP..., UM... product families.

THERMOMARK-RIBBON 110/50-TC - Ink ribbon

0801384

<https://www.phoenixcontact.com/us/products/0801384>



Ink ribbon, for THERMOMARK CARD for printing product groups UCT..., US..., and UM..., length: 50 m, roll length: 50 m, width: 110 mm, color: black

UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



THERMOMARK-RIBBON 110-TC - Ink ribbon

0801371

<https://www.phoenixcontact.com/us/products/0801371>



Ink ribbon, for THERMOMARK CARD for printing product groups UCT..., US..., and UM..., length: 300 m, roll length: 300 m, width: 110 mm, color: black

TMP-RIBBON 110 BK 100 - Ink ribbon cartridge

0803374

<https://www.phoenixcontact.com/us/products/0803374>



Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups UCT. ..., US..., and UM..., length: 70 m, roll length: 70 m, width: 110 mm, color: black

UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



BM ID-CARTR. BK - Ink cartridge

1044345

<https://www.phoenixcontact.com/us/products/1044345>



Replacement UV fluid, 23 ml, color: black

BM ID-CARTR. CY - Ink cartridge

1044346

<https://www.phoenixcontact.com/us/products/1044346>



Replacement UV fluid, 23 ml, color: cyan

UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



BM ID-CARTR. YE - Ink cartridge

1044348

<https://www.phoenixcontact.com/us/products/1044348>

Replacement UV fluid, 23 ml, color: yellow



BLUEMARK CLED-FLUID-CARTR. - Ink cartridge

5146662

<https://www.phoenixcontact.com/us/products/5146662>

Cartridge, for replacement, 20 ml UV color, black, including cleaning cartridge



UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



BLUEMARK FLUID-CARTRIDGE - Ink cartridge

5147421

<https://www.phoenixcontact.com/us/products/5147421>

Cartridge, for replacement, 28 ml UV color, black including cleaning cartridge



TMP-UCT-MAG28 - Magazine

0803372

<https://www.phoenixcontact.com/us/products/0803372>

Magazine, for the THERMOMARK PRIME and the THERMOMARK CARD, for accommodating UCT-WMCO ... (18x4), length: 0.166 m, width: 114 mm, height: 11.5 mm



UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



BM ID-MAG20 - Magazine

1044356

<https://www.phoenixcontact.com/us/products/1044356>



Infeed magazine for accommodating a max. of 20 UniCard sheets

BM ID-MAG40 - Magazine

1044357

<https://www.phoenixcontact.com/us/products/1044357>



Infeed magazine for accommodating a maxi. of 40 UniCard sheets

UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>




TOPMARK LASER-MAG UCT-A - Magazine

0803141

<https://www.phoenixcontact.com/us/products/0803141>

Magazine for the TOPMARK LASER, for accommodating UCT material automatically

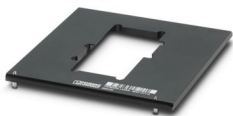

TOPMARK LASER-MAG UCT-M - Magazine

0803143

<https://www.phoenixcontact.com/us/products/0803143>

Magazine for the TOPMARK LASER, for accommodating UCT material manually



UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



THERMOMARK CARD - Thermal transfer printer

5146464

<https://www.phoenixcontact.com/us/products/5146464>

Thermal transfer printer for cards



THERMOMARK PRIME - Thermal transfer printer

5148888

<https://www.phoenixcontact.com/us/products/5148888>



Mobile thermal transfer printer for card materials, including power supply unit, Euro/US power cable, and USB cable. User manual printed in German and English. Magazine for UCT-TM... sheets and magazine for US-... cards. One packing unit each UCT-TM 6, US-EMLP (85,6x54), ink ribbon cartridge = 70 m

UCT-WMCO 4,1 (18X4) - Wire marking

0830785

<https://www.phoenixcontact.com/us/products/0830785>



BLUEMARK CLED - Printer

5147999

<https://www.phoenixcontact.com/us/products/5147999>

Printers with LED-UV technology for printing plastic labels in UniCard format.



THERMOMARK CARD-UCT-MAG28 - Magazine

0803205

<https://www.phoenixcontact.com/us/products/0803205>

Magazine for the THERMOMARK CARD printer, for accommodating UCT sheets (UCT-WMCO...(18x4))



Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com