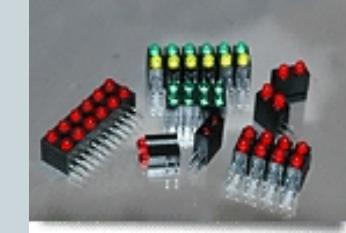


Part Number: **5530112216F****General Description**

Series	553
Configuration	3 mm Lens
Description	3 mm Bi - Level CBI
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Bi-Level Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Tinted, Diffused
Viewing Angle	45
LED Centerline	2.54mm

**5530112216F****check stock** 

This is a  
RoHS Compliant Product  
[To learn more click here](#)

**Absolute Maximum Ratings (Ta = 25°)**

Solder Temperature	260 for 5 secs
Operating Temperature	-25 to +85
Storage Temperature	-30 to +100

**Operating Characteristics**

	LED Position: 1	LED Position: 2
Color	Red	Green
LED Type	High Efficiency	High Efficiency
Peak Wave Length	650	563
Luminous Intensity Min	3.6	5.6
Luminous Intensity Typical	10	16
Forward Voltage Typical	2	2.1
Forward Voltage Max	3	3
Power Dissipation Max	60mW	75mW