




Part Number : [2033879010](#)

Product Description : Impel Test Cable Assembly,
Loopback, 30 AWG

Series Number : 203387

Status : Active

Product Category : High-Speed I/O Cable
Assemblies

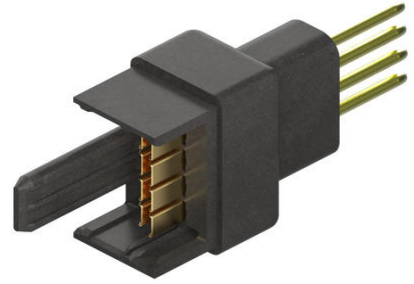

Documents and Resources


Drawings

[2033879010_sd.pdf](#)

[2033879010-PK.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	High-Speed I/O Cable Assemblies
Series	203387
Description	Impel Test Cable Assembly, Loopback, 30 AWG
Assembly Configuration	Single Ended Connector
Connector to Connector	Impel-to-Impel
Product Name	Impel
Type	Pluggable
UPC	191128750493

Physical

Cable Bundling	None
Cable Length	LOOPBACK
Circuits (Loaded)	16
Circuits (maximum)	16
Color - Resin	Black
Gender	Male
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Liquid Crystal Polymer (LCP)
Net Weight	5.850/g
Packaging Type	Bag
Release Style	N/A
Single Ended	Yes
Wire/Cable Type	Twinax
Wire Size (AWG)	30

This document was generated on May 19, 2026