



FLDWC0311-20-2 Product Details




Share



Print



Email

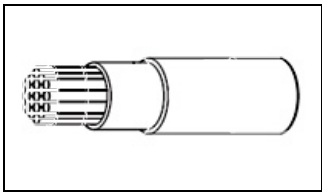

FLDWC0311-20-2

TE Internal Number: 639069-000

☐ Active

Commercial Wire

☐ Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Type = FlexLite DW
- Conductor Type = Tin-Plated Copper
- Conductor (Wire) Size = 20 AWG
- Temperature Range = -45 - 125 °C
- Color = Red

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

[Add to My Part List](#)



Request Sample



Find Similar Products

[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [DUAL WALL HOOKUP WIRE, RADIATION-CROSSLINKED, POLYAL...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Cable Type](#) = FlexLite DW
- Color = Red
- Cable Style = Primary
- Number of Conductors = 1

Electrical Characteristics:

- Number of Strands x AWG = 19 Strands x 32 AWG
- Voltage (VAC) = 600
- Resistance, Maximum (Ω /1000 ft@68°F) = 32

Body Features:

- Conductor Type = Tin-Plated Copper
- Wire Type = Stranded
- Cable Diameter Range (mm [in]) = 1.52 - 1.63 [0.060 - 0.064]
- Nominal Weight (kg/km) = 7.59

Configuration Features:

- Conductor (Wire) Size = 20 AWG
- Conductor Diameter (mm [in]) = 0.95 [0.037]

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Temperature Range (°C) = -45 - +125

Product Availability:

- Region = Americas, Asia/Pacific

Other:

- Brand = Raychem

Corporate Information

[About TE](#)

[Investors](#)

[News Room](#)

[Supplier Portal](#)

[Careers](#)

[Terms & Conditions](#)

Quick Links

[Check Distributor Inventory](#)

[Cross Reference Products](#)

[Find Documents & Drawings](#)

[Product Compliance Support Center](#)

[Site Map](#)

Customer Support

[Email or Chat With Us](#)

[Find a Phone Number](#)

[Search Knowledge Base](#)

[Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

