




**Part Number :** [152660318](#)

**Product Description :** 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 51.00mm Cable Length, Tin (Sn) Plating, 30 Circuits

**Series Number :** 15266

**Status :** Active

**Product Category :** Flat-Flexible Cable (FFC)

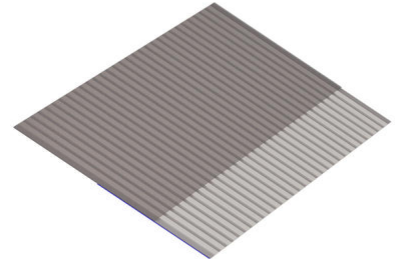

---

## Documents and Resources

### Drawings

[152660318 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


### Specifications

[PS-15266-001-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15266
Description	0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 51.00mm Cable Length, Tin (Sn) Plating, 30 Circuits
Comments	Contacts on opposite sides, Type D
Product Name	Premo-Flex FFC Jumper
UPC	884982437029

### Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

### Physical

Cable Length	51.00mm
Circuits (Loaded)	30
Contact Layout Type	D (opposite side)
Design Feature	Flexible
Material - Plating Mating	Tin
Net Weight	0.529/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 30 Circuits, Copper Alloy, Tin-Bismuth Plating	<a href="#"><u>5019513000</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>524353072</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>524373072</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>541043096</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 30 Circuits, Tin-Bismuth Plating	<a href="#"><u>541323097</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 30 Circuits	<a href="#"><u>781193010</u></a>
Easy-On FFC/FPC Connector,	<a href="#"><u>781273010</u></a>

0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 30 Circuits	
--	--

---

This document was generated on Dec 29, 2025