


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	50-00397	Connector, 4C audio plug, 3.5xL20.7 mm, brass, nickel plated, molding style	1	
2	30-00179	Wire, 3C BC, 28 AWG, 300V, 80C, 3.8 mm, foil + shield, PVC	1	
3	24-00265	Overmold, audio plug, 3.5 mm, twist lock, TIC	1	PVC, black
4	Heat Shrink	Heat shrink tubing, black	1	
5	Heat shrink	Heat shrink tubing, black	1	Covers shield wire

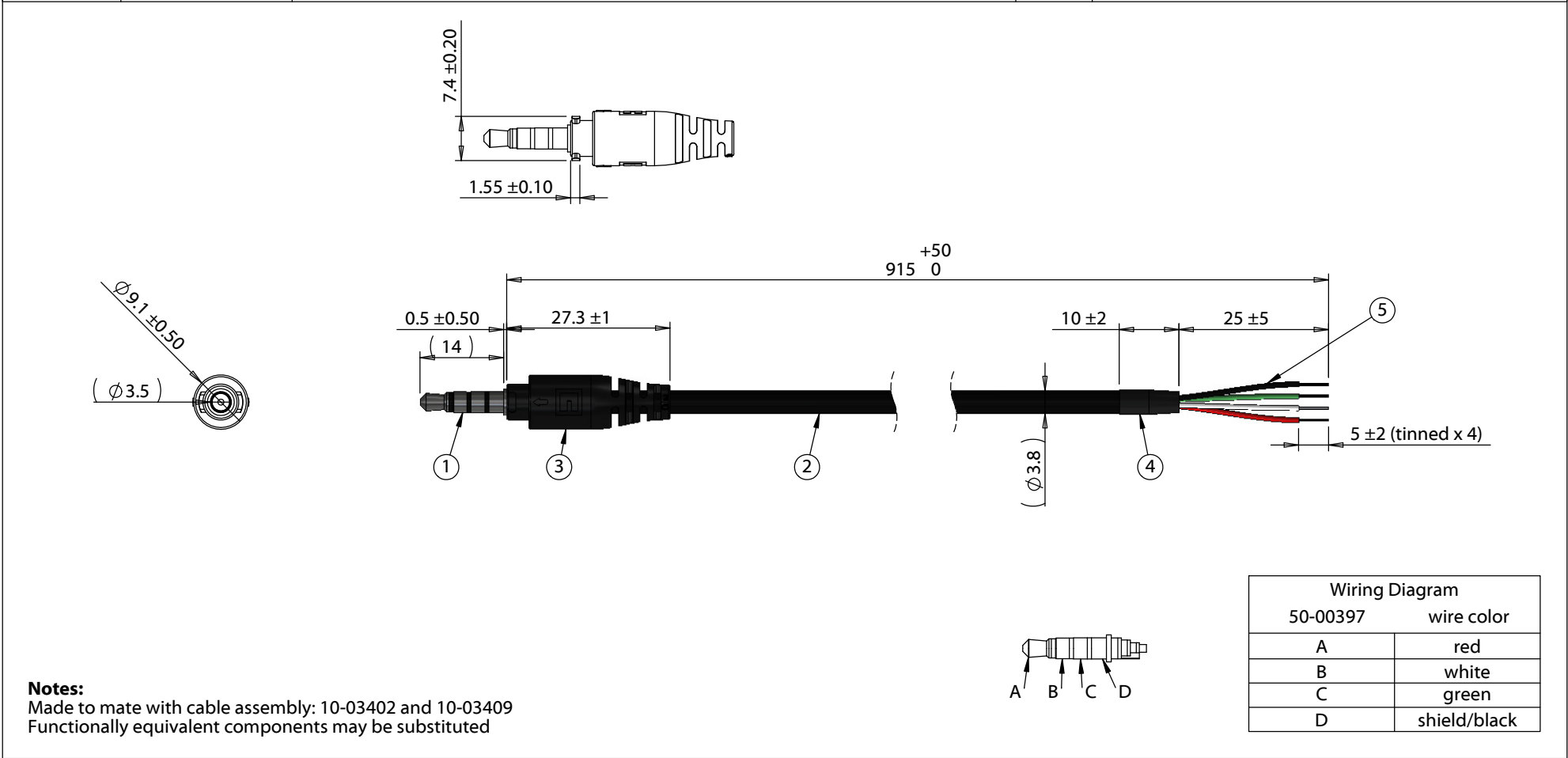

Notes:
 Made to mate with cable assembly: 10-03402 and 10-03409
 Functionally equivalent components may be substituted

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY tel 1.541.323.3228800 877.670.7118 fax 1.541.323.4202web tensility.com			
A	9/24/2019	Initial release	Verified:					
			Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Function test: no open, no short circuit, no intermittent				
				Description:	Size:		Part number:	
				Cable, 915 mm, 3.5 mm 4C 50-00397 twist lock audio plug to 5 mm tinned, 28 AWG, 30-00179	A		10-03401	
				Scale:		1:1	 	Sheet 1 of 1