

SEK CAB FLAT STD HF AWG28/7 24P 30,48m

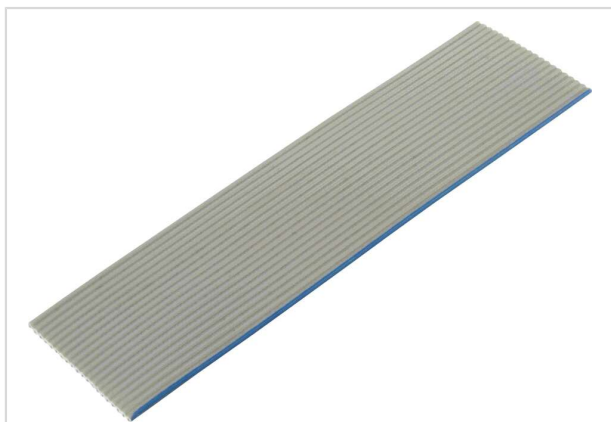


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 024 7001 900
Specification	SEK CAB FLAT STD HF AWG28/7 24P 30,48m
HARTING eCatalogue	https://b2b.harting.com/09180247001900

Version

Cable length	30.48 m
Number of cores	24
Core structure	AWG 28/7

Technical characteristics

Impedance	110 Ω
Limiting temperature	-40 ... +105 °C unmoved -20 ... +105 °C moved

Material properties

Material (cable)	Non-halogenated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	UL 1581 UL 758
CE	Yes



Pushing Performance
Since 1945

Commercial data

Packaging size	1
Net weight	1,524 g
Net weight	44 g/m
Country of origin	USA
European customs tariff number	85444993
GTIN	5713140024762
eCl@ss	27061801 Data and communication cable (copper)