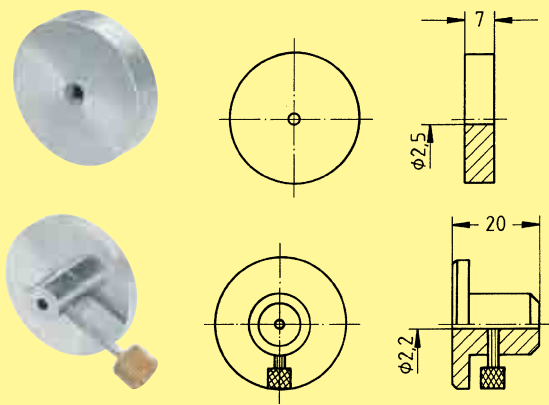
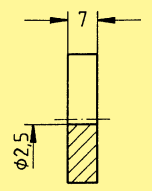
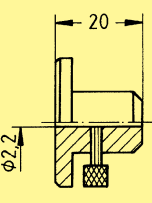


Identification	Part number	Drawing	Dimensions in mm
Polishing tool			
DIN 41 626	20 99 000 1092		
SC	20 99 000 1097		
POF ¹⁾ cable Ø 2.2	20 99 000 1093		
Fibre stripper			
0.3 mm	20 99 000 1041		
1 mm	20 99 000 1045		
0.18 / 0.3 mm	20 99 000 1046		
Crimping tool for following 1 mm POF ¹⁾ contacts Han D®, Han E® DIN 41 626 Ferrule F-SMA, -ST	20 99 000 1035		
HARTING crimping tool for F.O. connector (glass fibre) SW 4.3 mm SW 3.8 mm SW 4.95 mm			
	20 99 000 1031	for crimping the strain relief to the connector F.O. cable for glass fibre	
HARTING crimping tool for F.O. connector (plastic fibre) SW 6.95 mm SW 4.95 mm SW 3.0 mm			
	20 99 000 1033	for crimping the strain relief to the connector F.O. cable for plastic fibre	
Tools Epoxy adhesive glass fibre			
	20 80 001 9902	2 ml EPO-TEK 360 with hardener (10:1), 4 g foil pack	

¹⁾POF = Polymer optical fibre