


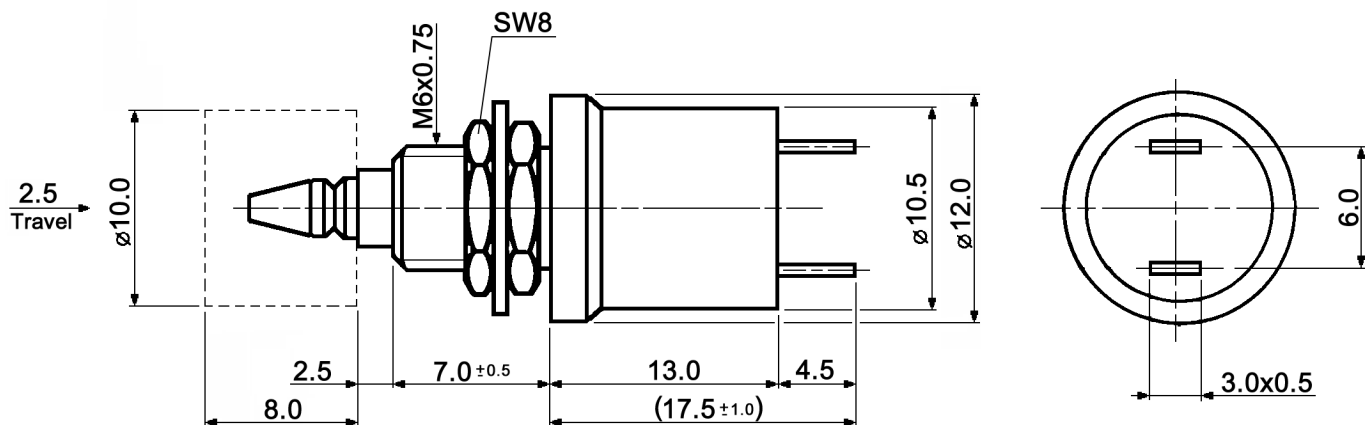

"x"	Switch function
B	on - (mom)
C	off - mom

Specifications:

Contact rating:	1A, 250V AC / 3A, 125V AC 2A, 24V DC
Contact resistance:	30mOhm max.
Insulation resistance:	500MOhm min. at 500V DC
Dielectric strength:	1 000V, 50Hz for the duration of 1 minute
Operating temperature:	-45°C to +110°C
Mechanical life:	min. 30 000 cycles
Soldering conditions:	hand-soldering: max.: 305°C, 3sec., 20W
Mounting:	bushing M6x0.75
Material:	Contacts: coin silver Terminals: solder tags



Tolerances:			Date	Name	MSP 103 xK	
			11/08	dr		
					20 09 05	
			knitter-switch			Page
						1/1
Modifications	Date	Name				