


Product data sheet

Specifications

NetShelter WX Vented Gland Plates

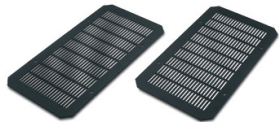

AR8355

Overview

Presentation	The NetShelter WX enclosure ships with a solid base and roof inserts. Users have the option of installing these ventilated plates in the roof, base, or both for increased air flow.
Lead time	Usually in Stock

Main

Product or component type	Ventilated roof
Number of cables	1

Physical

Colour	Black
Height	5 mm
Width	318 mm
Depth	140 mm
Net weight	0.68 kg
Mounting preference	No preference
Mounting mode	Not rack-mountable

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	5.8 cm
Package 1 Width	23.4 cm
Package 1 Length	32 cm
Package 1 Weight	0.98 kg

Contractual warranty

Warranty	2 years repair or replace
----------	---------------------------

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

 Materials and Substances	
Packaging made with recycled cardboard	No
Packaging without single use plastic	No
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)
REACH Regulation	REACH Declaration

Use Again

 Repack and remanufacture	
End of life manual availability	End of Life Information
Take-back	No
WEEE Label	 The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins