


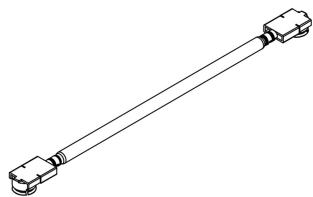

Part Number : [734120280](#)
Product Description : MCRF-to-MCRF, 0.81mm
Cable Diameter, Length 65.00mm, 50 Ohms
Series Number : 73419
Status : Active
Product Category : RF Cable Assemblies



Documents & Resources

Drawings
[Drawing 734120280_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)8585-DC (23 Jan 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	RF Cable Assemblies
Series	73419
Description	MCRF-to-MCRF, 0.81mm Cable Diameter, Length 65.00mm, 50 Ohms
Assembly Configuration	Dual Ended Connectors
Connector to Connector	MCRF-to-MCRF
Product Family	RF Connectors, RF Cable Assemblies and RF Components
Product Name	MCRF
Type	RF Cable Assembly
UPC	822348803958

Electrical

Impedance	50Ω
-----------	-----

Physical

Cable Length	65.00mm
Gender	Plug/Plug
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Net Weight	0.120/g
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	0.81mm, Coaxial

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

This document was generated on Mar 26, 2024