
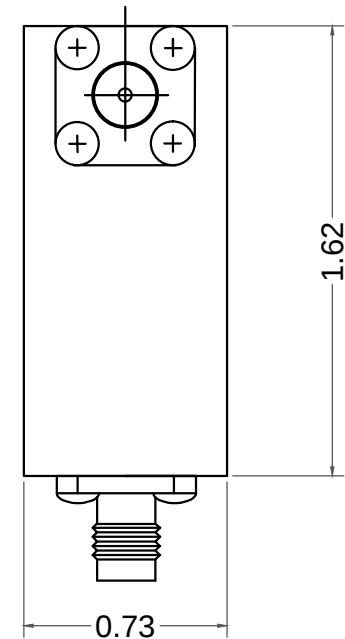


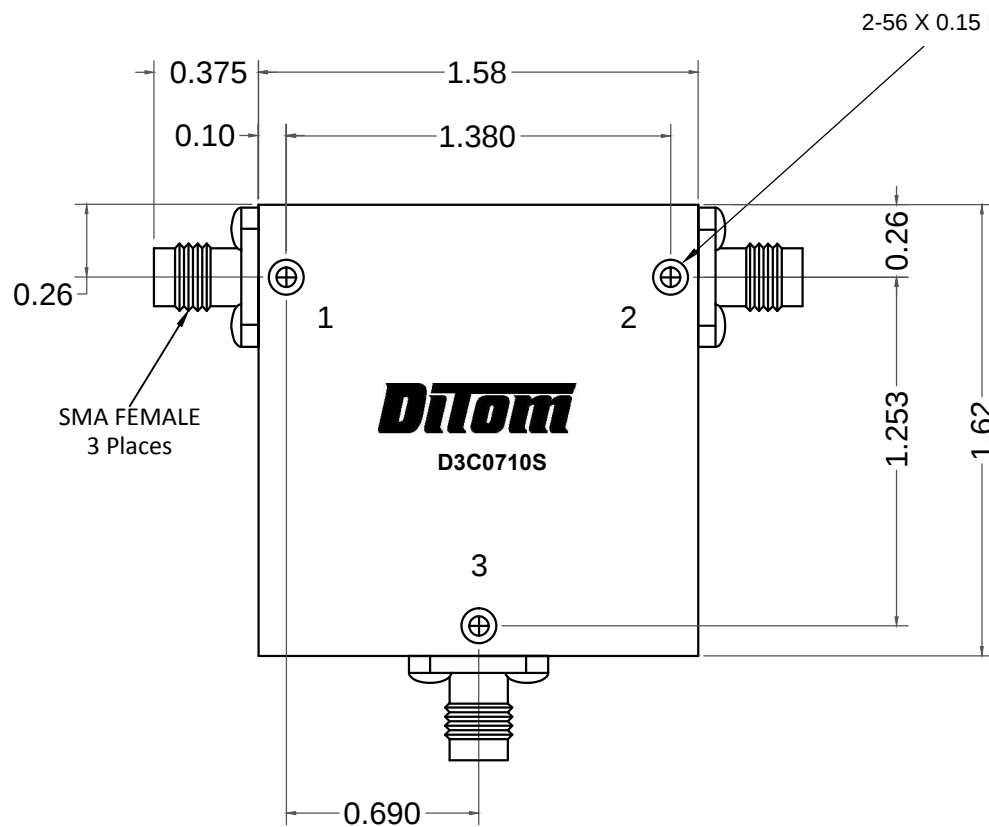

ELECTRICAL SPECIFICATIONS

FREQUENCY RANGE (MHz):	698 - 1000
ISOLATION (dB):	16 MIN
INSERTION LOSS (dB):	0.60 MAX
VSWR:	1.40 MAX
POWER: AVG (ALL PORTS):	300W
PEAK:	750W

MECHANICAL SPECIFICATIONS

CONNECTORS:	SMA-FEMALE, PASSIVATED STAINLESS STEEL
CONTACT PINS:	BERYLLIUM COPPER, GOLD PLATE
OPERATING TEMPERATURE:	-20° to +65°C
WEIGHT (APPROX):	4.80 OUNCES

DIMENSIONS IN INCHES, UNLESS OTHERWISE SPECIFIED		 Fresno, California, USA	
TOLERANCE XX±0.03 XXX±0.010	TITLE 698 - 1000 MHz Circulator		
SCALE 3:1	MODEL NO D3C0710S		REV