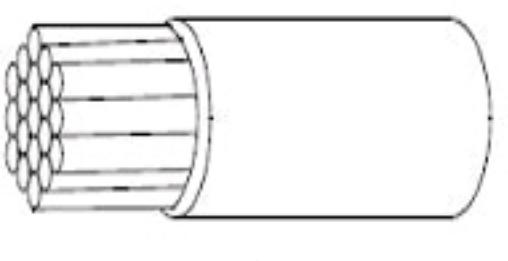


22759/32-26-9 Product Details

[!\[\]\(e3f8612927870f2e0f9f5989e6dd3064_img.jpg\) Share](#) [!\[\]\(a86c7d1c9cb81c81614634a31267440d_img.jpg\) Print](#) [!\[\]\(ce158fc5e55633398941d0898ae45661_img.jpg\) Email](#)

Spec 44, Spec 55 and Spec RCW Wire and Cable

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

22759/32-26-9

TE Internal Number: 216111-002

[Active](#)[!\[\]\(4f6bf54ae7e4144a72d78316053e412d_img.jpg\) Add to My Part List](#)[!\[\]\(3342c215b2a8b663596a81468d5dc314_img.jpg\) Request Sample](#)[!\[\]\(56549452e01ca28bdf2500ced9653143_img.jpg\) Find Similar Products](#)[!\[\]\(1f56542a42e2413e44a2b2023033aa2e_img.jpg\) Buy Product](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [Wire, Radiation-Crosslinked, Modified, ETFE-Insulate...](#) (PDF, English)

Related Products:

- [Tooling](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Cable Type](#) = Spec 55
- [Cable Style](#) = Primary
- Number of Conductors = 1

Conditions for Usage:

- Temperature Range (°C) = -65 – +150
- Wire Size - Details = 26 AWG 0.15 mm², 0.00024 in², 19 x 38 AWG

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Operation/Application:

- Application = General Purpose - Lightweight

Body Features:

- Wire Size (AWG/CM) = 26 AWG
- Conductor Type = Tin-Plated Copper
- Wire Color = White
- Nominal Outside Diameter (mm [in]) = 0.81 [0.032]
- Wire Diameter (mm [in]) = 0.81 [0.032]
- Conductor O.D. (mm [in]) = 0.50 [0.020]

Packaging Features:

- Wire Source = United States

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M22759/32-26-9
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = Raychem

Corporate Information[Who We Are](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)**Quick Links**[Check Distributor Inventory](#)[Cross Reference](#)[Find Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)**Customer Support**[Email or Chat With Us](#)[Find a Phone Number](#)[Search Knowledge Base](#)[Manage your Account](#)**Keep Me Informed**

Receive TE News, Events & Technology Updates

Enter your email address 