


UC-EM (17,5X9) YE - Snap-in markers



0827494

<https://www.phoenixcontact.com/us/products/0827494>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

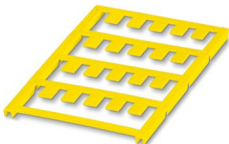

Snap-in markers, Sheet, yellow, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: snapped, lettering field size: 17.5 x 9 mm, Number of individual labels: 20

Your advantages

- The markers, which are supplied in uniform sheets, can be labeled quickly and easily using the BLUEMARK LED
- The UC-EM ... UniCard labeling range includes markers for devices and switching devices from a wide range of manufacturers
- The format automatically ensures printing with a high degree of positioning accuracy
- The wide temperature range means that the labels can be used in control cabinets as well as the field
- The sheets provide space for including function texts

Commercial data

| | |
|--------------------------------------|---------------------|
| Item number | 0827494 |
| Packing unit | 10 pc |
| Minimum order quantity | 10 pc |
| Sales key | BG10 |
| Product key | BG2417 |
| Catalog page | Page 304 (C-3-2019) |
| GTIN | 4046356458054 |
| Weight per piece (including packing) | 11.67 g |
| Weight per piece (excluding packing) | 10.21 g |
| Customs tariff number | 39269097 |
| Country of origin | PL |

UC-EM (17,5X9) YE - Snap-in markers



0827494

<https://www.phoenixcontact.com/us/products/0827494>

Technical data

Product properties

| | |
|-------------------------------------|-------------------|
| Product type | Device marking |
| Data management status | |
| Article revision | 05 |
| Marking | |
| Number of individual labels | 20 |
| Number of individual labels per row | 5 |
| Identification technology | UV LED technology |

Mounting

| | |
|---------------|---------|
| Mounting type | snapped |
|---------------|---------|

Material specifications

| | |
|---|--------------------------------|
| RoHS compliant | yes |
| Color | yellow |
| Material | PA |
| Flammability rating according to UL 94 | V2 |
| Temperature index of insulation material (DIN EN 60216-1 (VDE 0304-21)) | 120 °C |
| Fire protection for rail vehicles (DIN EN 45545-2) R22 | HL 1 - HL 2 |
| Fire protection for rail vehicles (DIN EN 45545-2) R23 | HL 1 - HL 2 |
| Fire protection for rail vehicles (DIN EN 45545-2) R24 | HL 1 - HL 2 |
| Components | free from silicone and halogen |

Environmental and real-life conditions

Test for substances that would hinder coating with paint or varnish

| | |
|--------|-------------|
| Result | Test passed |
|--------|-------------|

UV resistance

| | |
|---------------|--------------------------------|
| Specification | ISO 4892-2:2013-03 (following) |
| Result | Test passed |
| Test duration | 96 h |

Wipe resistance of inscriptions

| | |
|---|--|
| Specification | DIN EN 61010-1 (VDE 0411-1):2011-07 |
| | DIN EN 62208 (VDE 0660-511):2012-06 (in parts) |
| Isopropyl [CAS No. 67-63-0] | Test passed |
| n-Hexane [CAS No. 110-54-3] | Test passed |
| Water + Petroleum ether [CAS No. 64742-82-1] | Test passed |

UC-EM (17,5X9) YE - Snap-in markers



0827494

<https://www.phoenixcontact.com/us/products/0827494>

Testing in a condensation changing climate in the presence of sulfur dioxide

| | |
|---------------|-------------------|
| Specification | DIN 50018:2013-05 |
| Result | Test passed |
| Climate level | AHT 1.0 S |
| Cycles | 2 |

Salt spray test

| | |
|---------------|---------------------------|
| Specification | DIN EN 60068-2-11:2000-02 |
| Result | Test passed |

Ambient conditions

| | |
|---|---|
| Ambient temperature (operation) | -40 °C ... 120 °C |
| Recommended storage conditions | 23 °C/50 % relative humidity. Storage in a dry and dark place in the original packaging is recommended. |
| Recommended ambient temperature (storage/transport) | 23 °C |
| Recommended humidity (storage/transport) | 50 % |

Dimensions

| | |
|-------------------|----------|
| Width | 17.5 mm |
| Text field width | 17.50 mm |
| Text field height | 9.00 mm |
| Length | 9 mm |

Standards and regulations

| | |
|-----------------|-----------------------------|
| Wipe resistance | DIN EN 61010-1 (VDE 0411-1) |
|-----------------|-----------------------------|

UC-EM (17,5X9) YE - Snap-in markers



0827494

<https://www.phoenixcontact.com/us/products/0827494>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-11.0 | 27281103 |
| ECLASS-12.0 | 27281103 |
| ECLASS-13.0 | 27281103 |

ETIM

| | |
|----------|----------|
| ETIM 9.0 | EC001288 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39131500 |
|-------------|----------|

UC-EM (17,5X9) YE - Snap-in markers



0827494

<https://www.phoenixcontact.com/us/products/0827494>

Environmental product compliance

| | |
|---|----------------------------|
| EU RoHS | |
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
| EU REACH SVHC | |
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |

UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



Accessories

BLUEMARK ID - Printer

1003334

<https://www.phoenixcontact.com/us/products/1003334>



Monochrome printer with UV inkjet technology and integrated "MARKING system app" identification software. 7" touch color display for printing plastic labels in UC, UCT, US, and UM format, as well as metal labels.

BLUEMARK ID COLOR - Printer

1002329

<https://www.phoenixcontact.com/us/products/1002329>



CMYK multicolor printer with UV inkjet technology, with integrated "MARKING system app" identification software, 7" touch color display for printing plastic labels in UC, UCT, and UM format, as well as metal labels.

UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



PLOTMARK - Marking plotter

0804499

<https://www.phoenixcontact.com/us/products/0804499>

Marking plotter for the entire portfolio of UC marking materials and materials in sheet and strip format.

 


CMS-P1-PLOTTER - Marking plotter

5144615

<https://www.phoenixcontact.com/us/products/5144615>

Marking plotter, weight: 8 kg, length: 0.66 m, width: 440 mm, height: 125 mm, color: silver



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



BM ID-CARTR. BK - Ink cartridge

1044345

<https://www.phoenixcontact.com/us/products/1044345>



Replacement UV fluid, 23 ml, color: black

BM ID-CARTR. CY - Ink cartridge

1044346

<https://www.phoenixcontact.com/us/products/1044346>



Replacement UV fluid, 23 ml, color: cyan

UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



BM ID-CLEANING CARTR. - Cleaning cartridge

1044350

<https://www.phoenixcontact.com/us/products/1044350>

Replacement cleaning cartridge



BLUEMARK CLED-FLUID-CARTR. - Ink cartridge

5146662

<https://www.phoenixcontact.com/us/products/5146662>

Cartridge, for replacement, 20 ml UV color, black, including cleaning cartridge



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



BLUEMARK FLUID-CARTRIDGE - Ink cartridge

5147421

<https://www.phoenixcontact.com/us/products/5147421>

Cartridge, for replacement, 28 ml UV color, black including cleaning cartridge



CMS-DISPOSABLE-PEN 0,25 TR - Marker pen

5146685

<https://www.phoenixcontact.com/us/products/5146685>

Disposable pen, incl. adapter, integrated ink cartridge and pen station, writing thickness: 0.25 mm



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



CMS-DISPOSABLE-PEN 0,35 TR - Marker pen

5146686

<https://www.phoenixcontact.com/us/products/5146686>

Disposable pen, incl. adapter, integrated ink cartridge and pen station, writing thickness: 0.35 mm



CMS-INK-TR-C5 - Ink cartridge

5146684

<https://www.phoenixcontact.com/us/products/5146684>

Ink cartridge, special black ink, 5 cartridges of 1 ml each, for high demands



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



CMS-PEN 0,25 - Marker pen

5067815

<https://www.phoenixcontact.com/us/products/5067815>

Marker pen, incl. adapter, ink tank and reservoir, 0.25 mm nib



CMS-PEN 0,35 - Marker pen

5067828

<https://www.phoenixcontact.com/us/products/5067828>

Marker pen, incl. adapter, ink tank and reservoir, 0.35 mm nib



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



CMS-PEN 0,50 - Marker pen

5067831

<https://www.phoenixcontact.com/us/products/5067831>

Marker pen, incl. adapter, ink tank and reservoir, 0.5 mm nib



CMS-R-FLUID-TR - Cleaning fluid

5146750

<https://www.phoenixcontact.com/us/products/5146750>

Cleaning fluid, 30 ml, for the CMS-PEN ... and CMS-DISPOSABLE-PEN ...



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



CMS-R-FLUID-TR-C2 - Cleaning cartridge

5146752

<https://www.phoenixcontact.com/us/products/5146752>



Cleaning cartridges with replacement sealing caps, 2 cartridges with 10 ml cleaning fluid each and 2 caps for the CMS-PEN ... and CMS-DISPOSABLE-PEN ...

BM ID-MAG20 - Magazine

1044356

<https://www.phoenixcontact.com/us/products/1044356>



Infeed magazine for accommodating a max. of 20 UniCard sheets

UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



BM ID-MAG40 - Magazine

1044357

<https://www.phoenixcontact.com/us/products/1044357>

Infeed magazine for accommodating a maxi. of 40 UniCard sheets



P1 UC-MAG 1 - Magazine

5146079

<https://www.phoenixcontact.com/us/products/5146079>

Magazine, for CMS-P1-PLOTTER and PLOTMARK, for accommodating UC-TM.
..., UC-TMN..., UC-WMC 3,1..., UC-WMTBA...



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



P1 UC-MAG 6 - Magazine

5146121

<https://www.phoenixcontact.com/us/products/5146121>

Magazine, for CMS-P1-PLOTTER and PLOTMARK, for accommodating UC-EMP..., UC-EMLP...



CMS-R-SET-TR - Cleaning set

5146751

<https://www.phoenixcontact.com/us/products/5146751>

Cleaning set, consisting of: 1x cleaning cup, 2x cleaning cartridges with 10 ml cleaning fluid each and 2x replacement sealing caps for the CMS-PEN ... and CMS-DISPOSABLE-PEN ...



UC-EM (17,5X9) YE - Snap-in markers

0827494

<https://www.phoenixcontact.com/us/products/0827494>



BLUEMARK CLED - Printer

5147999

<https://www.phoenixcontact.com/us/products/5147999>

Printers with LED-UV technology for printing plastic labels in UniCard format.



Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com