

# UCT-EM (20X9) - Snap-in markers



0801471  
<https://www.phoenixcontact.com/us/products/0801471>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Snap-in markers, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: snapped, lettering field size: 20 x 9 mm, Number of individual labels: 24

## Your advantages

- The UCT-EM ... UniCard marking range includes markers for devices and switching devices from a wide range of manufacturers
- The markers, which are supplied in uniform sheets, can be marked quickly, easily, and precisely using the card printers
- The sheets provide additional space for project information and function text that can be helpful during further assembly
- The multi-section marking strips are easy to fit and can be easily separated if required
- Marking service: Phoenix Contact can custom-mark all UniCard markers according to your specifications

## Commercial data

Item number	0801471
Packing unit	10 pc
Sales key	BG10
Product key	BG2418
Catalog page	Page 311 (C-3-2019)
GTIN	4046356673129
Weight per piece (including packing)	13.6 g
Weight per piece (excluding packing)	12.7 g
Customs tariff number	39269097
Country of origin	PL

# UCT-EM (20X9) - Snap-in markers



0801471

<https://www.phoenixcontact.com/us/products/0801471>

## Technical data

### Product properties

Product type	Device marking
Marking	
Number of individual labels	24
Number of individual labels per row	6
Identification technology	Thermal transfer for sheets and cards, UV LED technology, direct laser marking

### Mounting

Mounting type	snapped
---------------	---------

### Material specifications

RoHS compliant	yes
Color	white
Material	PC
Flammability rating according to UL 94	V0
Relative insulation material temperature index (Elec., UL 746 B)	130 °C
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R24	HL 1 - HL 3
Components	free from silicone and halogen

### Environmental and real-life conditions

Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

UV resistance

Specification	ISO 4892-2:2013-03 (following)
Result	Test passed
Test duration	96 h

Wipe resistance of inscriptions

Specification	IEC 61010-1:2010-06
	DIN EN 62208 (VDE 0660-511):2012-06 (in parts)

Testing in a condensation changing climate in the presence of sulfur dioxide

Specification	DIN 50018:2013-05
Result	Test passed
Climate level	AHT 1.0 S
Cycles	2

Salt spray test

Specification	DIN EN 60068-2-11:2000-02
---------------	---------------------------

# UCT-EM (20X9) - Snap-in markers



0801471

<https://www.phoenixcontact.com/us/products/0801471>

Result	Test passed
--------	-------------

Ambient conditions

Ambient temperature (operation)	-40 °C ... 120 °C
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %

Dimensions

Width	20 mm
Length	9 mm

Standards and regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

# UCT-EM (20X9) - Snap-in markers



0801471

<https://www.phoenixcontact.com/us/products/0801471>

## Classifications

### ECLASS

ECLASS-11.0	27281103
ECLASS-12.0	27281103
ECLASS-13.0	27281103

### ETIM

ETIM 9.0	EC001288
----------	----------

### UNSPSC

UNSPSC 21.0	39131500
-------------	----------

# UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## Accessories

### THERMOMARK CARD 2.0 - Thermal transfer printer

1085267

<https://www.phoenixcontact.com/us/products/1085267>



Thermal transfer printer for card materials, including Euro/US power cable and USB cable. User manual printed in German and English. Magazine for UCT-TM... sheets and magazines for US-... cards. One packing unit each UCT-TM 6, US-EMLP (85,6x54), ink ribbon = 50 m

---

### THERMOMARK PRIME - Thermal transfer printer

5148888

<https://www.phoenixcontact.com/us/products/5148888>



Mobile thermal transfer printer for card materials, including power supply unit, Euro/US power cable, and USB cable. User manual printed in German and English. Magazine for UCT-TM... sheets and magazine for US-... cards. One packing unit each UCT-TM 6, US-EMLP (85,6x54), ink ribbon cartridge = 70 m

# UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## BLUEMARK ID - Printer

1003334

<https://www.phoenixcontact.com/us/products/1003334>



Monochrome printer with UV LED technology and integrated "MARKING system app" identification software. 7" touch color display for printing plastic tags in UC, UCT, US, and UM format, as well as metal labels.

---

## BLUEMARK ID COLOR - Printer

1002329

<https://www.phoenixcontact.com/us/products/1002329>



CMYK multicolor printer with UV LED technology, with integrated "MARKING system app" identification software, 7" touch color display for printing plastic tags in UC, UCT, and UM format, as well as metal labels.

## UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## TOPMARK NEO - Laser marker

1012015

<https://www.phoenixcontact.com/us/products/1012015>



Laser marking system for the efficient marking of metal or plastic marking material from the LS..., UCT..., UC.../PP..., UM... product families.

---

## THERMOMARK-RIBBON 110/50-TC - Ink ribbon

0801384

<https://www.phoenixcontact.com/us/products/0801384>



Ink ribbon, for THERMOMARK CARD for printing product groups UCT..., US..., and UM..., length: 50 m, roll length: 50 m, width: 110 mm, color: black

# UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## THERMOMARK-RIBBON 110-TC - Ink ribbon

0801371

<https://www.phoenixcontact.com/us/products/0801371>



Ink ribbon, for THERMOMARK CARD for printing product groups UCT..., US..., and UM..., length: 300 m, roll length: 300 m, width: 110 mm, color: black

---

## TMP-RIBBON 110 BK 100 - Ink ribbon cartridge

0803374

<https://www.phoenixcontact.com/us/products/0803374>



Ink ribbon cartridge, for THERMOMARK PRIME for printing product groups UCT. ..., US..., and UM..., length: 70 m, roll length: 70 m, width: 110 mm, color: black



# UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## BM ID-CARTR. BK - Ink cartridge

1044345

<https://www.phoenixcontact.com/us/products/1044345>



Replacement UV fluid, 23 ml, color: black

---

## BM ID-CARTR. CY - Ink cartridge

1044346

<https://www.phoenixcontact.com/us/products/1044346>



Replacement UV fluid, 23 ml, color: cyan

## UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## BM ID-CARTR. YE - Ink cartridge

1044348

<https://www.phoenixcontact.com/us/products/1044348>

Replacement UV fluid, 23 ml, color: yellow



---

## BLUEMARK CLED-FLUID-CARTR. - Ink cartridge

5146662

<https://www.phoenixcontact.com/us/products/5146662>

Cartridge, for replacement, 20 ml UV color, black, including cleaning cartridge



## UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## BLUEMARK FLUID-CARTRIDGE - Ink cartridge

5147421

<https://www.phoenixcontact.com/us/products/5147421>

Cartridge, for replacement, 28 ml UV color, black including cleaning cartridge



---

## TMP-UCT-MAG15 - Magazine

0803357

<https://www.phoenixcontact.com/us/products/0803357>

Magazine, for the THERMOMARK PRIME and the THERMOMARK CARD, for accommodating UCT-EM (20x9), length: 0.166 m, width: 114 mm, height: 11.5 mm



# UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## BM ID-MAG20 - Magazine

1044356

<https://www.phoenixcontact.com/us/products/1044356>



Infeed magazine for accommodating a max. of 20 UniCard sheets

---

## BM ID-MAG40 - Magazine

1044357

<https://www.phoenixcontact.com/us/products/1044357>



Infeed magazine for accommodating a maxi. of 40 UniCard sheets

## UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>

 


## TOPMARK LASER-MAG UCT-A - Magazine

0803141

<https://www.phoenixcontact.com/us/products/0803141>

Magazine for the TOPMARK LASER, for accommodating UCT material automatically



---

## TOPMARK LASER-MAG UCT-M - Magazine

0803143

<https://www.phoenixcontact.com/us/products/0803143>

Magazine for the TOPMARK LASER, for accommodating UCT material manually



## UCT-EM (20X9) - Snap-in markers

0801471


<https://www.phoenixcontact.com/us/products/0801471>



### KLM 2 - Terminal strip marker carrier

0807575

<https://www.phoenixcontact.com/us/products/0807575>

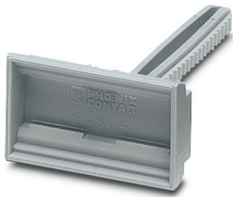

Terminal strip marker carrier, adjustable height, for CLIPFIX 15, CLIPFIX 35, and CLIPFIX 35-5 end brackets, can be marked using snap-in labels

---

### GKM 1 GY - Cable marker carrier

1750498

<https://www.phoenixcontact.com/us/products/1750498>



Cable marker carrier, gray, unlabeled, mounting type: clip on, cable diameter range: 0 ... 5.2 mm, lettering field size: 20 x 8 mm

## UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## GKM 2 GY - Cable marker carrier

1750485

<https://www.phoenixcontact.com/us/products/1750485>



Cable marker carrier, gray, unlabeled, mounting type: clip on, cable diameter range: 4.8 ... 11 mm, lettering field size: 20 x 8 mm

---

## THERMOMARK CARD - Thermal transfer printer

5146464

<https://www.phoenixcontact.com/us/products/5146464>



Thermal transfer printer for cards

# UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## BLUEMARK CLED - Printer

5147999

<https://www.phoenixcontact.com/us/products/5147999>



Printers with LED-UV technology for printing plastic labels in UniCard format.

---

## TOPMARK LASER US - Laser marker

0803297

<https://www.phoenixcontact.com/us/products/0803297>



Laser marker and MARKING NOTEBOOK with English operating system and English keyboard, incl. CLIP-PROJECT PROFESSIONAL software and installed drivers, user manual, sheet magazine, card magazine, and 120 V extraction unit



# UCT-EM (20X9) - Snap-in markers

0801471

<https://www.phoenixcontact.com/us/products/0801471>



## THERMOMARK CARD-UCT-MAG15 - Magazine

0830402

<https://www.phoenixcontact.com/us/products/0830402>

Magazine for the THERMOMARK CARD printer, for accommodating UCT sheets  
UCT-EM (20 x 9)



---

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)