



Inserter/extractor handle, type IET, grey, bottom (Rear I/O 6 U top)

SCHROFF

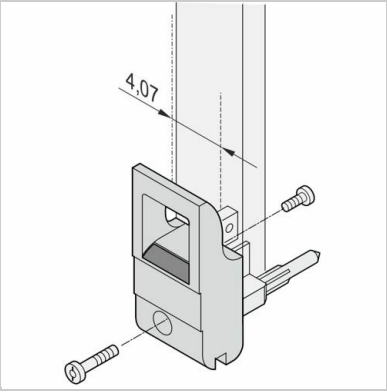

Other Views

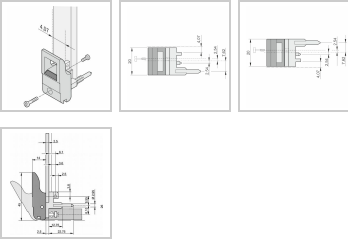

Catalog Number: 20817-660

Back To Product

- lever/key UL 94 V-0
- with locking
- slotted Pozidrive collar screw, M2.5 x 12.3, St, nickel-plated
- suitable for insertion and extraction forces up to 700 N (per pair)
- codable to IEEE 1101.10 and IEC 60297-3-103
- in accordance with IEEE 1101.10 and IEC 60297-3-102
- panhead screw with Torx, M2.5 x 7, St, nickel-plated
- suitable for fitting of microswitches
- with integrated alignment pin for perforated strip
- block die-cast zinc, nickel plated

Specification:

- IEC 60297-3-103
- IEEE 1101.10
- IEC 60297-3-102

Handle:

IET

Type:

Individual Components

Standard:

- CompactPCI
- VME64x

Individual Component Type:

Handle

Delivery Includes:

assembled

Product family:

Plug-in units



Select product specifications before modifying or adding to project list or requesting a quote.

Version-defining

Bottom ▾

Qty-defining

10 ▾

[Clear Selection](#)

Quantity

1

Add Item to Project List +

Documents

-  Main Catalog - Plug-in units
-  User manual, coding IEEE

Links

-  Native CAD files


Technical Data

Qty	PU 10 pieces
Material	Plastic Lever, die-cast zinc base, UL 94 V-0
Finish	Lever: light grey, RAL 7035 Button: black, RAL 9005
Configuration	3U Bottom Front / 6U Top Front / 6U Bottom

Delivery Comprises:

Item	Quantity	Description
1	1	Zn die-cast with integrated alignment pin for perforated strip and IEEE 1101.10 guide rail
2	1	Lever, plastic PC, UL 94 V-0
3	1	Key, plastic PC, UL 94 V-0
4	1	Pozidrive collar screw, M2.5 × 12.3, St, nickel-plated
5	1	Pan head screw with Torx, M2.5 × 7, St, nickel-plated

 Accessories



Label strips for IEL/IET handle, white, sheet with 210pcs (19x9,5), PU 1 pcs

60817-340

[Add Item to Project List +](#)

Microswitch for IEL/IET handle, PU 10 pcs

20817-606

[Add Item to Project List +](#)

EXPLORE

[About Us](#)
[Services & Capabilities](#)
[News & Events](#)
[Newsletter Subscriptions](#)
[Strategic Partnerships](#)
[Investor Relations](#)

CONTACT

[Customer Service](#)
[Find a Sales Office or Distributor](#)
[Global Locations](#)
[Product Compliance & Certifications](#)
[Partner Login](#)

DOWNLOAD

[Download Center](#)
[Reference Projects](#)
[Videos](#)
[Product Configurators](#)
[Warranties and Terms of Sale & Procurement](#)

© 2018 nVent. All rights reserved | [Privacy Policy](#) | [Terms of Use](#) | [Cookie Policy](#) | [Imprint](#) | [Site Map](#)

Connect With Us

