


PART
NAME

10" EXHAUST FAN


PART
No.

FN-1282

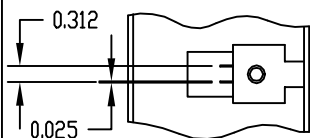

FAN

HOUSING - ALUMINUM
 STRUTS on: - DISCH
 BEARING - BALL
 VOLTAGE - 115
 FREQUENCY - 50/60
 CFM - 535
 AMPS - .78/.70
 WATTS - 51
 NPL - 6.2
 OPERATING TEMP. RANGE: -20°C TO +60°C
 WEIGHT - 1990 GRAMS


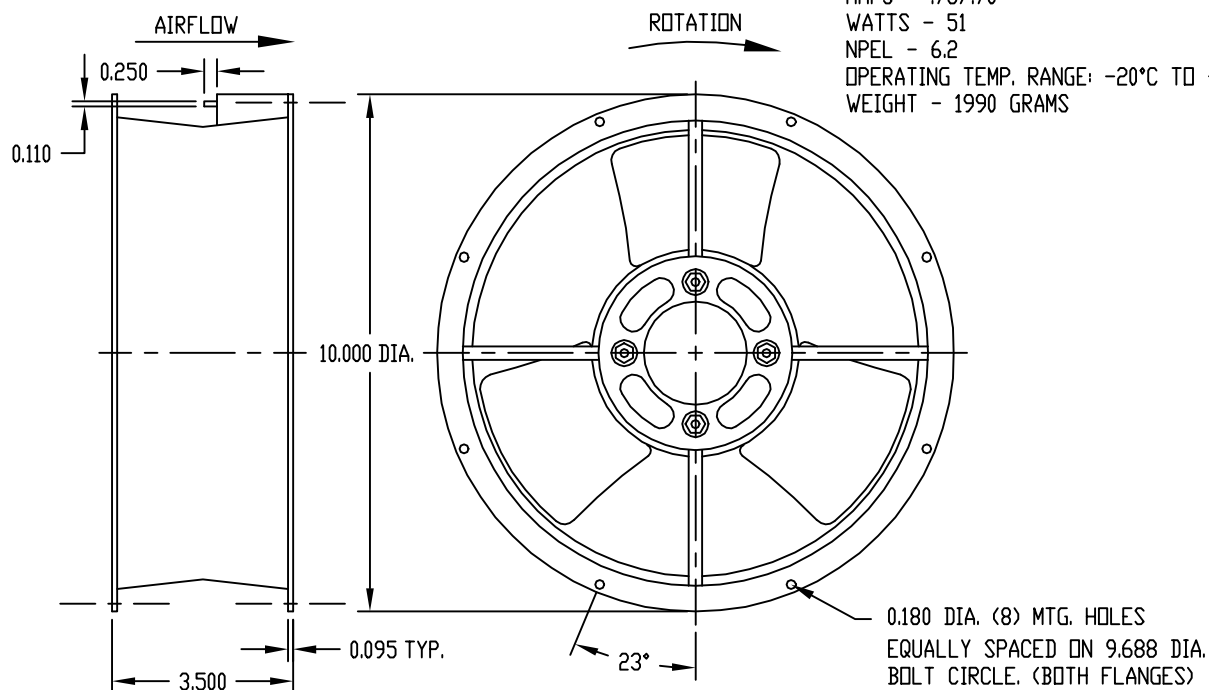


NOTE: SUPPLIED WITH ALL MOUNTING HARDWARE.

GUARD

MATERIAL: STEEL WIRE

FINISH: ZINC PLATED

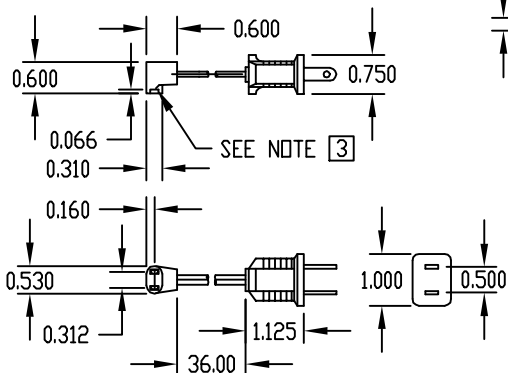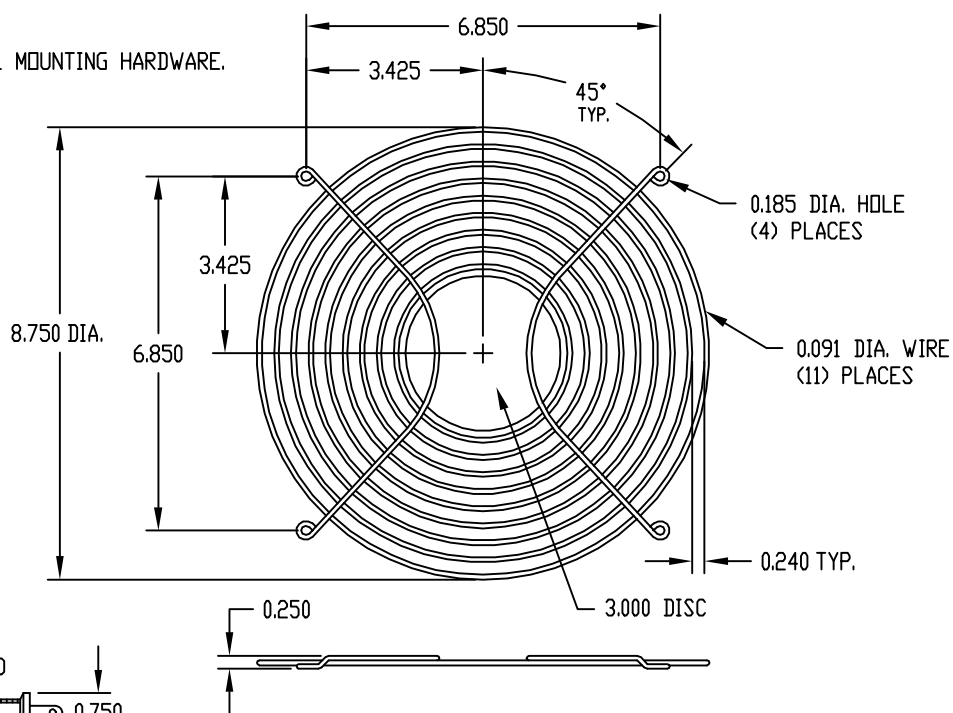

FAN CORD

[1] MATERIAL:

- a) LEADS-SPT-1 18AWG 105° C. INSULATION. (COLOR BLACK)
- b) PLUG-PVC UL 105° C. (COLOR BLACK)
- c) TERMINAL-PHOSPHOR BRONZE

[2] UL RATED-E61080, CSA APPROVED-LR35931[3] TERMINALS TO BE PRE-TINNED & MUST BE FREE OF FLASH.