


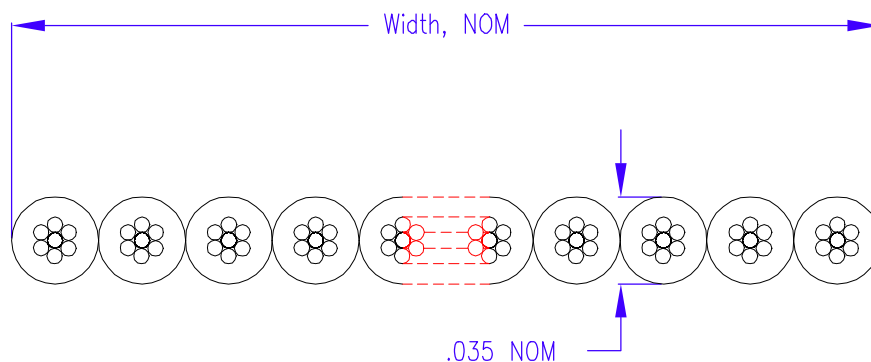

Part Number	Count	Width
111-2803-010	10	.35" NOM (8,89mm NOM)
111-2803-015	15	.53" NOM (13,34mm NOM)
111-2803-020	20	.70" NOM (17,78mm NOM)
111-2803-030	30	.105" NOM (26,67mm NOM)

For Other Conductor Counts, Contact Factory: Width= .035" X (# of Conductors)

All Dimensions in Inches Unless Otherwise Noted.

PHYSICAL

Conductors: 28 AWG 7/36 Tinned Copper
 Insulation: .010" Nom PVC
 Color Code: Brown, Red, Orange, Yellow, Green, Blue, Violet, Gray, White, Black and Repeat
 Temp. Rating: 105°C

ELECTRICAL

Voltage Rating: 300 V
 Current Rating: 1.3 A @ 10°C Rise Above Ambient
 Insulation Res.: 10^{10} ohms - 10 ft Min.
 Cable Style: UL AWM Style 2693 (105°C, 300V)
 CSA: Available upon request

DRAWN	PROD ENG	QA	MKT	P/ECN#		DRAWING NO. 111-2803-0XX	AMPHENOL SPECTRA-STRIP 720 SHERMAN AVE TEL (203) 281-3200 HAMDEN CT 06514 FAX (203) 281-5872	Rev A
FITS 12/11/02						TITLE: Spectra-Bond® Parallel		SHEET 1 of 1
						Conductor Cable		