


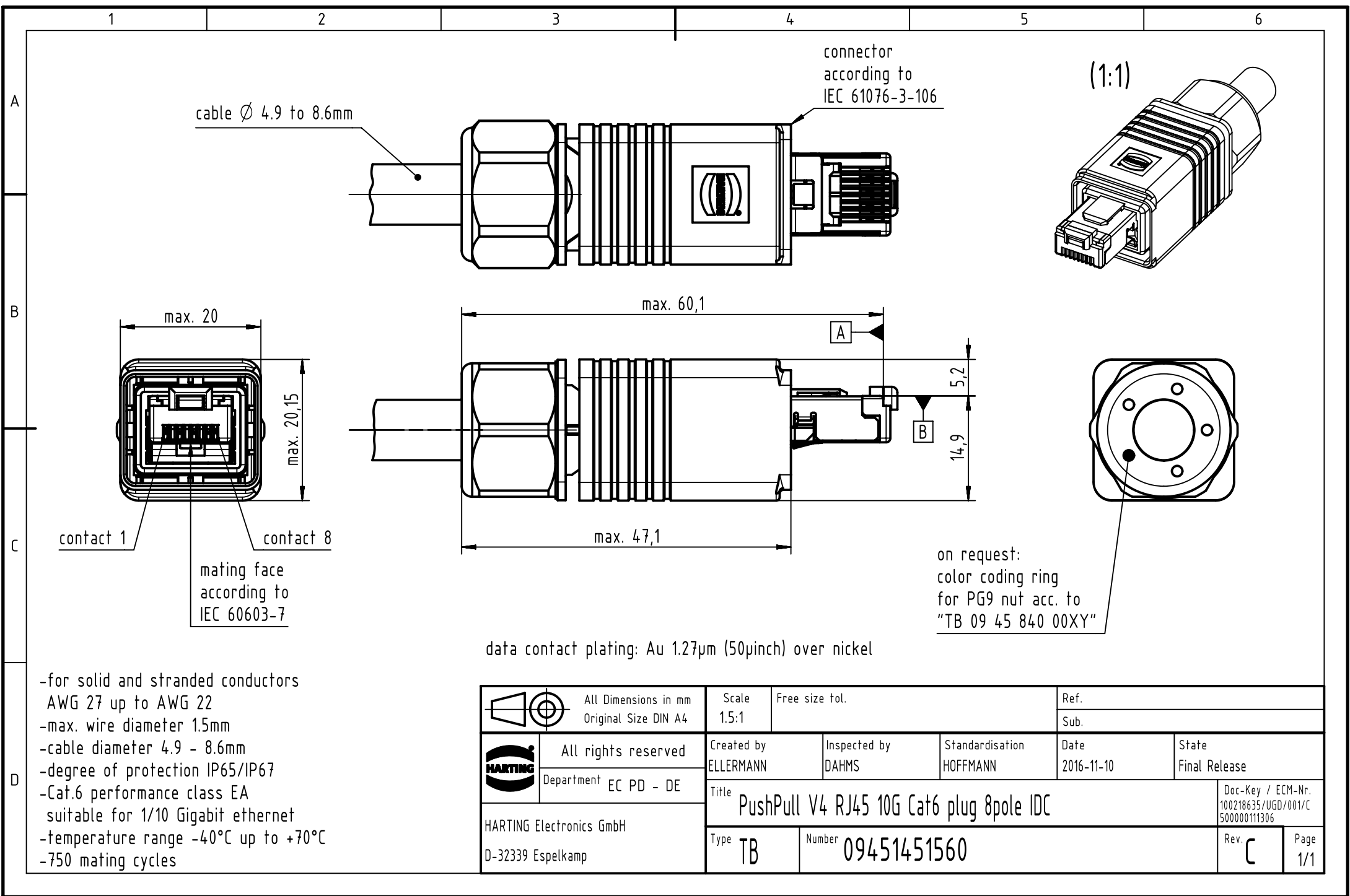

A
B
C
D

- for solid and stranded conductors
AWG 27 up to AWG 22
- max. wire diameter 1.5mm
- cable diameter 4.9 - 8.6mm
- degree of protection IP65/IP67
- Cat.6 performance class EA
suitable for 1/10 Gigabit ethernet
- temperature range -40°C up to +70°C
- 750 mating cycles

data contact plating: Au 1.27µm (50pinch) over nickel

		All Dimensions in mm Original Size DIN A4		Scale 1.5:1		Free size tol.		Ref.							
								Sub.							
		All rights reserved		Created by ELLERMANN		Inspected by DAHMS		Standardisation HOFFMANN		Date 2016-11-10		State Final Release			
		Department EC PD - DE		Title PushPull V4 RJ45 10G Cat6 plug 8pole IDC								Doc-Key / ECM-Nr. 100218635/UGD/001/C 500000111306			
HARTING Electronics GmbH D-32339 Espelkamp				Type TB		Number 09451451560						Rev. C		Page 1/1	