

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0731160074

Status:


Active

Overview:

RF Connectors and Microwave Products

Description:

MCRF-to-Pigtail, 0.81mm Cable Diameter, Length 76.2mm, H18, 50 Ohms, One Piece Per Bag

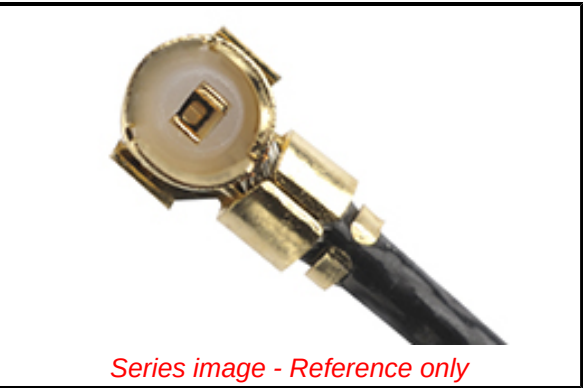

Documents:

Drawing (PDF)

Application Specification AS-33472-100-CH-001 (PDF)

Product Specification PS-160074-0001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Application Specification AS-33472-100-001 (PDF)

General	
Product Family	Cable Assemblies
Series	73116
Assembly Configuration	Single Ended Connector
Connector to Connector	MCRF-to-Pigtail
Overview	RF Connectors and Microwave Products
Product Name	MCRF, RF
Type	RF Cable Assembly
UPC	884982813618
Physical	
Cable Length	76.20mm (3.000")
Circuits (Loaded)	0
Gender	Plug-Pigtail
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Single Ended	Yes
Wire/Cable Type	Coaxial
Electrical	
Impedance	50Ω
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-33472-100-001, AS-33472-100-CH-001
Product Specification	PS-160074-0001-001
Sales Drawing	SD-73116-007-001

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

73116 Series

Mates With

734120110 MCRF, 50 Ohm, Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION