



2-Way 2.1mm DC Barrel Jack Splitter Squid

PRODUCT ID: 1351

IN STOCK

1

ADD TO CART

1-9

10-99

100+

ADD TO WISHLIST

[DESCRIPTION](#)

[TECHNICAL DETAILS](#)



DESCRIPTION

Double up your power adapters with this wonderfully simple 2-way power jack splitter. All you have to do is connect a standard 5.5mm/2.1mm sized plug into one end, and behold, two identical plugs to use! We like the rugged molding on these adapters, and they're really handy when you have a project with multiple pluggable devices.

Raspberry Pi Model A & Flora Color Sensor! New Products 5/4/2013





2-Way 2.1mm DC Barrel Jack Splitter Squid (0:25)

TECHNICAL DETAILS

- Weight: 21.2g
- Total Length: ~300mm / ~12"
- Male Cable Length: 171mm / 6.7"
- Max Width: 19mm / .75"
- Jack-side cable is 24AWG. Plug side cables are 24AWG.




MAY WE ALSO SUGGEST...



12V DC 1000mA (1A)



Male DC Power adapter -

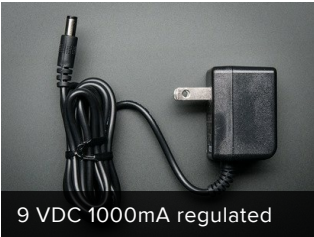

9 VDC 1000mA regulated



2.1mm female/male barrel



Female DC Power adapter -



4-Way 2.1mm DC Barrel Jack



In-line power switch for



5V 2A (2000mA) switching



5.5 / 2.1mm Barrel



USB to 2.1mm Male Barrel



2.1mm DC Barrel Jack to 1st



USB to 2.1mm DC Booster

DISTRIBUTORS [EXPAND TO SEE DISTRIBUTORS](#)

[CONTACT](#)

"This is not the age of

[SUPPORT](#)

[DISTRIBUTORS](#)

[EDUCATORS](#)

[JOBS](#)

[FAQ](#)

[SHIPPING & RETURNS](#)

[TERMS OF SERVICE](#)

[PRIVACY & LEGAL](#)

[ABOUT US](#)

ENGINEERED IN NYC Adafruit®

pamphleteers. It is the age of engineers. The spark-gap is mightier than the pen" - Lancelot Hogben



4.9 ★★★★★
Google
Customer Reviews