


Data Sheet | Item Number: 706-7753/304-100
System cable; for WAGO-I/O-SYSTEM, 750 Series; 2 x 8 analog inputs or outputs;
Length: 1 m; Conductor cross-section: 0.14 mm²
<https://www.wago.com/706-7753/304-100>



Similar to illustration

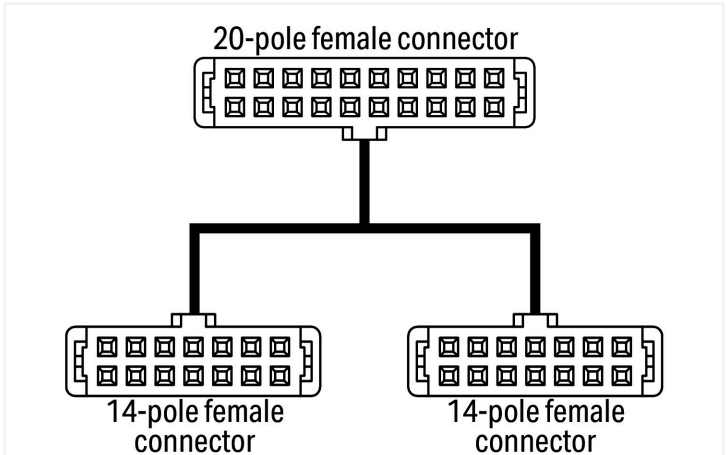

Color coding acc. to DIN VDE 47100 Cable 1; Channel 1-8		14 poles flat connector		20 poles flat connector	
	Pin number	Wiring	Pin number	Signal	
White	1	CH1	1	DO1	
Brown	2	CH2	2	DO2	
Green	3	CH3	3	DO3	
Yellow	4	CH4	4	DO4	
Grey	5	CH5	5	DO5	
Pink	6	CH6	6	DO6	
Blue	7	CH7	7	DO7	
Red	8	CH8	8	DO8	
Black	9	+24V	17	+24V	
Violet	10	0V	18	0V	

Color coding acc. to DIN VDE 47100 Cable 2; Channel 9-16		14 poles flat connector		20 poles flat connector	
	Pin number	Wiring	Pin number	Signal	
White	1	CH9	9	DO9	
Brown	2	CH10	10	DO10	
Green	3	CH11	11	DO11	
Yellow	4	CH12	12	DO12	
Grey	5	CH13	13	DO13	
Pink	6	CH14	14	DO14	
Blue	7	CH15	15	DO15	
Red	8	CH16	16	DO16	
Black	9	+24V	19	+24V	
Violet	10	0V	20	0V	

Short description:
WAGO's Interface Cables provide fast and easy connection of WAGO I/O Modules equipped with a 20-pole pluggable connector. The following WAGO I/O Modules and Interface Adapters are compatible:

- 750-1500 (16 DO) --> 857-981 (DO)
- 750-1502 (8 DO/8 DI) --> 857-981 (DO) and 857-982 (DI)
- The cables are available in 1-, 2- and 3-meter lengths; each has one 20-pole or two 14-pole pluggable connectors at both ends.
- They are suitable for system wiring when paired with 857-981 and 857-982 Interface Adapters.

Notes	
Note	When using more than 10 wires, the maximum current per wire must be reduced to 0.7 A.

Electrical data	
Inputs/outputs	2 x 8 analog inputs or outputs
Operating voltage	≤ 35 VAC/VDC
Current per wire (max.)	1 A



Connection data

Cable type	LiYY	Connection 1	
Color code	per DIN VDE 47100	Pluggable connector	Pluggable connector per DIN 41651; fe- male connector
		Pole number 1	20
		Connection type 1	System
		Wire cross-section	0.14 mm²

Connection 2	
Connector 2	Pluggable connector per DIN 41651; fe- male connector
Pole number 2	14
Connection type	System

Connection 3	
Connector 3	Pluggable connector per DIN 41651; fe- male connector
Pole number 3	14
Connection type	System

Physical data

Cable length	1 m
--------------	-----

Material data

Fire load	0 MJ
Weight	97 g

Environmental requirements

Ambient temperature (operation)	-20 ... +50 °C
---------------------------------	----------------

Commercial data

Product Group	30 (WAGO France)
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	FR
GTIN	4050821034209
Customs tariff number	85444290900

Product classification

UNSPSC	26121604
eCl@ss 10.0	27-06-03-11
eCl@ss 9.0	27-06-03-11
ETIM 9.0	EC000237
ETIM 8.0	EC000237
ECCN	NO US CLASSIFICATION



Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 706-7753/304-100	

Documentation				
Bid Text				
706-7753/304-100	26.11.2018	docx 15.25 KB		
706-7753/304-100	19.02.2019	xml 3.70 KB		

CAD/CAE-Data	
CAE data	
WSCAD Universe 706-7753/304-100	

1 Compatible Products	
1.1 Optional Accessories	
1.1.1 Interface module	
1.1.1.1 Interface adapters	



Item No.: 857-981 Interface adapter; 14-pole; High-side switching input	Item No.: 857-982 Interface adapter; 14-pole; High-side switching output
--	---

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com