



# L60 Series

## 0.230" (5.9mm) Watertight LED Panel Mount Indicator



L60 Series offers a robust body with drip-proof protection in a small package

### Application

- Automotive
- Aerospace
- Industrial
- Medical
- Mining
- Military Instrumentation
- Safety and Emergency
- Transportation
- Vending and Gaming Machines


### Key Features

- Watertight
- Tinted diffused LEDs
- Reflective chrome-plated body
- 45° viewing angle
- Maximum panel thickness 0.070" (1.7mm)
- Mounting hardware provided
- 6" (152.4mm) wire leads, 24 AWG
- Mounting hole 0.232"  $\pm 0.003$ " (5.9mm  $\pm 0.1$ mm)
- Operating Temperature: -20 °C to +100 °C
- Storage Temperature: -40 °C to +100 °C
- RoHS compliant

## Product Dimensions

| Part Numbers | Output Color | Design Voltage/<br>Current (Vf/If) | Max Voltage/<br>Current (Vf/If) | Typical Intensity<br>(mcd) | Peak Wavelength<br>(nm) |
|--------------|--------------|------------------------------------|---------------------------------|----------------------------|-------------------------|
| L60D-R5-W    | Red          | 5VDC / 17mA                        | 5.5VDC / 20mA                   | 60                         | 635                     |
| L60D-A5-W    | Amber        | 5VDC / 17mA                        | 5.5VDC / 20mA                   | 30                         | 583                     |
| L60D-G5-W    | Green        | 5VDC / 17mA                        | 5.5VDC / 20mA                   | 44                         | 565                     |
| L60D-R12-W   | Red          | 12VDC / 16mA                       | 14VDC / 19mA                    | 60                         | 635                     |
| L60D-A12-W   | Amber        | 12VDC / 16mA                       | 14VDC / 19mA                    | 30                         | 583                     |
| L60D-G12-W   | Green        | 12VDC / 16mA                       | 14VDC / 19mA                    | 44                         | 565                     |
| L60D-R28-W   | Red          | 28VDC / 15.8mA                     | 30VDC / 17.5mA                  | 60                         | 635                     |
| L60D-A28-W   | Amber        | 28VDC / 15.8mA                     | 30VDC / 17.5mA                  | 30                         | 583                     |
| L60D-G28-W   | Green        | 28VDC / 15.8mA                     | 30VDC / 17.5mA                  | 44                         | 565                     |

## Product Dimensions

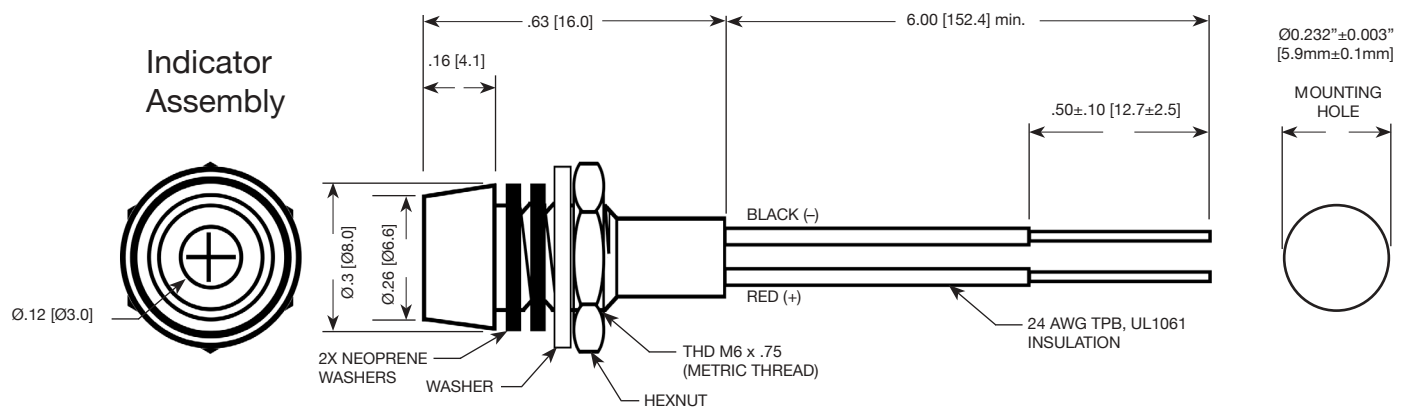

### Notes:

All dimensions are in inches [mm]

## Compliances and Approvals

