

You are here: [Home](#) ▶ [Piezo Buzzer](#) ▶ [Piezo Indicator](#) ▶ [Wire](#) ▶ KPEG250

All in one search

Tag

Title

Category

[Piezo Buzzer](#)

[Piezo Indicator](#)

[Panel Mounting](#)

[Pin](#)

[SMD](#)

[Water Proof](#)

[Wire](#)

[Piezo Siren](#)

[Piezo Sounder](#)

[Piezo Transducer](#)

[Piezo Speaker](#)

[Piezo Tweeter](#)

[Magnetic Buzzer](#)

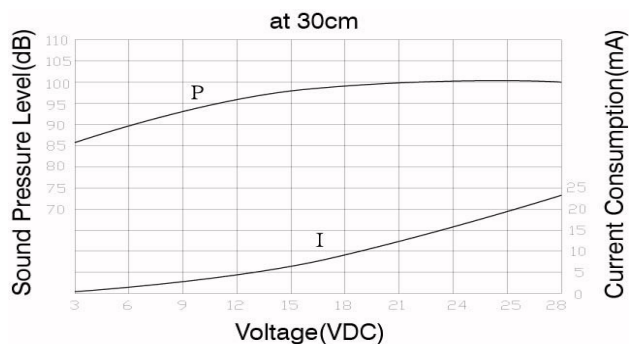
[Micro Speaker](#)

[Dynamic Receiver](#)

[ECM](#)

[Audio Products](#)

KPEG250

[Print](#)


Additional Info

Rated Frequency (Hz):	3500+/-500
Rated Voltage (Vp-p / VDC):	Max 28
Current Consumption (mA):	Max 6 @12VDC
Sound Pressure Level (dB):	Min 85dB@30cm/12VDC
Operating Temperature (°C):	-30 ~ + 85
Storage Temperature (°C):	-40 ~ + 95
Dimension (mm):	Φ28.0x25.4
Tone:	Continuous

 [Like](#) [Sign Up](#) to see what your friends like.

Tagged under [Piezo Wire Indicator 35KHz 12VDC](#)

More in this category: [« KPEG263](#) [KPEG251 »](#)

[back to top](#)

