


Horizontal Rail, Front, Type L-KD, Light, Short Lip, 63 HP

CATALOG NUMBER

34560-163

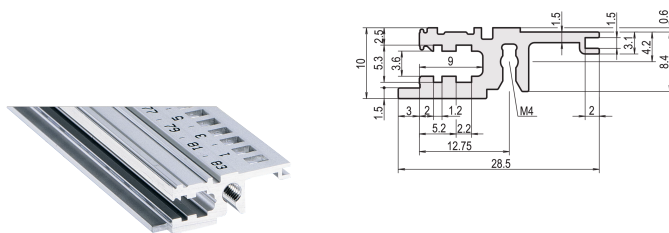

Combinations of horizontal rails and side panels

„+“ can be combined. „-“ combination not recommended

	Standard rail	Standard rail with short lip	Standard rail with short lip and rounded end	Standard rail with short lip and rounded end and chamfered end
Standard rail	-	+	+	+
Standard rail with short lip	+	+	+	+
Standard rail with short lip and rounded end	+	+	+	+
Standard rail with short lip and rounded end and chamfered end	+	+	+	+
Side panel	+	+	+	+
Light x L	+	+	+	+
Fluorescent F	+	+	+	+
Heavy x H	+	+	+	+
Rugged x R	+	+	+	+

Side panel

Light x L

Fluorescent F

Heavy x H

Rugged x R

The horizontal rail with a short lip makes a clean design to the assembled front panel.

CERTIFICATIONS



FEATURES

Standard rail at the front

Installation at top and bottom

Short lip (L-KD)

< 28 HP not to print

Aluminum extrusion, anodized finish, conductive contact surface

PRODUCT ATTRIBUTES

Product Type: Horizontal Rail

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Type: Light, KD

Rack Width: 63HP

Package Quantity: 1

Finish: Anodized

Material: Aluminum

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

©2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

This document is system-generated.

nVent.com/SCHROFF | 2