


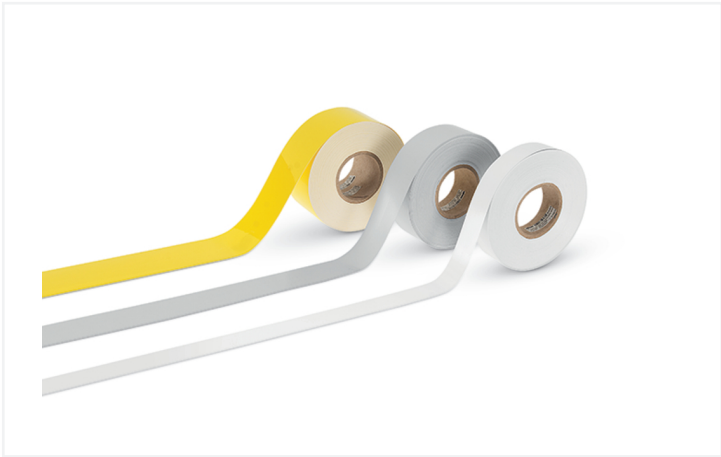

Color: ■ yellow

Similar to illustration



Technical data	
Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	20 m; 1 line
Printing device	Smart Printer (thermal transfer printer)

Physical data	
Width	46 mm
Depth	0.2 mm
Strip width	46 mm

Mechanical data	
Mounting type	Sticking
Smear resistance	in conjunction with 258-5005 Ink Ribbon

Material data	
Color	yellow
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	Acrylic; permanent
Halogen-free	Yes
Weight	0 g
Fire load	0 MJ



Environmental requirements		
Ambient temperature (storage)		+10 ... +21 °C
Ambient temperature (operation)		-40 ... +150 °C
Relative humidity		40 ... 50 %

Commercial data		
PU (SPU)		1 pcs
Packaging type		Box
Country of origin		DE
GTIN		4055143378970
Customs tariff number		39199080888

Product Classification		
UNSPSC		55121612
eCl@ss 10.0		27-40-06-29
eCl@ss 9.0		27-40-06-29
ETIM 9.0		EC001288
ETIM 8.0		EC001288
ECCN		NO US CLASSIFICATION

Environmental Product Compliance		
RoHS Compliance Status		Compliant,No Exemption

Downloads		
Environmental Product Compliance		
Compliance Search		
Environmental Product Compliance		↓
210-876/000-002		

Documentation			
Operating Instructions			
2009-110 Information on printing material	1 28.08.2020	pdf 1190.09 KB	↓