



Pomona Female 0.1" Socket to Banana Plug - 24" - Red

PRODUCT ID: 2666

DISCONTINUED

[DESCRIPTION](#)

[TECHNICAL DETAILS](#)



 
DESCRIPTION

We have a couple of these handy **Pomona Female 0.1" Socket to Banana Plug 24"** cables! Great for use with your benchtop equipment, these are the highest quality cables and will last you years, if not decades.

This is the **24"** long Red version. [We also carry this cable in black.](#)

This Female Socket to Banana Plug cable is terrific for prototyping or for use as a jumper on

circuit boards, you can shove a ~22AWG solid core wire into the header or [use some extra long header to turn these into male-type header contacts](#)



TECHNICAL DETAILS

- [Datasheet](#)
- Length: 24" / 610mm
- AWG: 22
- Contact Material: Beryllium Copper
- Socket Finish: Gold plated
- Banana Plug Finish: Nickle plated


For product support, replacement parts and warranty for all Pomona products, [click here!](#)

Product Dimensions: 127.0mm x 101.6mm x 7.0mm / 5.0" x 4.0" x 0.3"

Product Weight: 9.0g / 0.3oz




MAY WE ALSO SUGGEST...

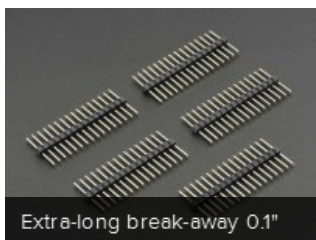

Extra-long break-away 0.1"




Half-size breadboard

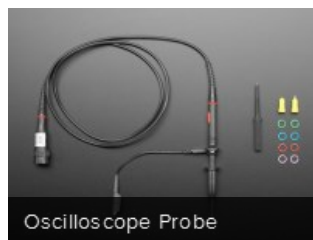


Oscilloscope Probe



SMD Component Testing

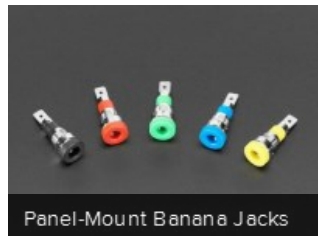

Panel-Mount Banana Jacks

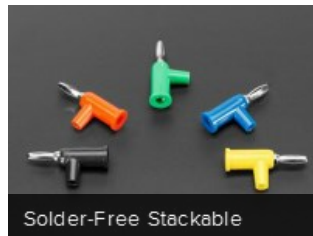

Solder-Free Stackable

4.6 ★★★★★
Google
Customer Reviews