

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


0039010133

Status:

Planned for Obsolescence

Description:

2.50mm (.098") Pitch Wire-to-Board Receptacle Housing, Low Profile, 13 Circuits

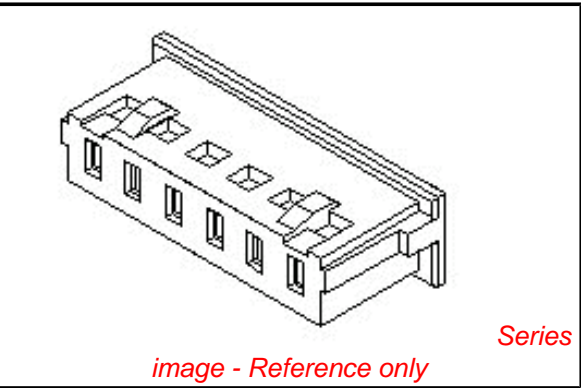

Documents:

Drawing (PDF)

Product Specification PS-5480-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	5480
Application	Signal
Product Name	N/A
Physical	
Circuits (maximum)	13
Color - Resin	Natural
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm (.098")
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Old Part Number

5480-13

Reference - Drawing Numbers

Product Specification

PS-5480-001, RPS-5480-001, RPS-5480-002, RPS-5480-003, RPS-5483-001, RPS-5483-002

Sales Drawing

SD-5480-N

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS

Need more information on product environmental compliance?

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

5480Series

Mates With

5483 , 5484

Use With

5479

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION