

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0731160035

Status:


Active

Overview:

RF Connectors, RF Cable Assemblies and RF Components

Description:

MCRF-to-MCRF, 1.32mm Cable Diameter, Length 152.4mm, H25, 50 Ohms, One Piece Per Bag

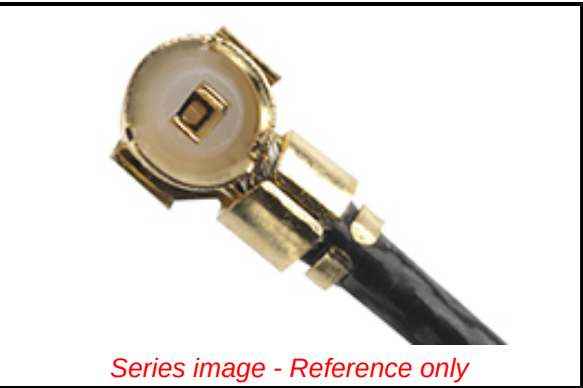

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
General	
Product Family	Cable Assemblies
Series	73116
Assembly Configuration	Dual Ended Connectors
Connector to Connector	MCRF-to-MCRF
Overview	RF Connectors, RF Cable Assemblies and RF Components
Product Name	MCRF, RF
Taxonomy	RF Cable Assemblies
Type	RF Cable Assembly
UPC	884982813113
Physical	
Cable Length	152.40mm (6.000")
Circuits (Loaded)	0
Gender	Plug/Plug
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Resin	Polyester
Net Weight	0.600/g
Number of Rows	1
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	Coaxial
Electrical	
Impedance	50Ω
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-73116-003-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

73116 Series

Mates With

734120110 MCRF, 50 Ohm, Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION