

Part Number : 150200436

Product Description : 0.50mm Pitch Premo-Flex FFC


Jumper, Opposite Side Contacts (Type D), 152.00mm

Cable Length, Gold (Au) Plating, 40 Circuits

Series Number : 15020

Status : Active

Product Category : Flat-Flexible Cable (FFC)

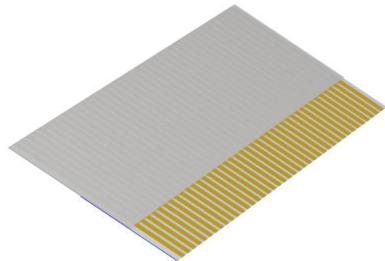

Documents & Resources

Drawings

[150200436_sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[PS-15020-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 33
China RoHS	ⓘ per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2020)9139-DC (19 Jan 2021)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15020
Description	0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 152.00mm Cable Length, Gold (Au) Plating, 40 Circuits
Comments	Contacts on opposite sides, Type D
Product Name	Premo-Flex FFC Jumper
UPC	884982178984

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Physical

Cable Length	152.00mm
Circuits (Loaded)	40
Contact Layout Type	D (opposite side)
Design Feature	Flexible
Material - Plating Mating	Gold
Net Weight	2.299/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 40 Circuits, Phosphor Bronze, Gold Plating	<u>5019514030</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 40 Circuits, Copper Alloy, 125°C Operating Temperature, Gold Plating	<u>5019514050</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FBH1 Series, Right-Angle, Dual Contact, 1.00mm Height, 40 Circuits, Gold over Nickel Plating	<u>5034804000</u>
Easy-On FFC/FPC Connector 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 40 Circuits, Gold over Nickel Plating	<u>5051104091</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 40 Circuits, Gold Plating	<u>525594052</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 40 Circuits, Gold Plating	<u>541044031</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm	<u>541324062</u>

Height, 40 Circuits, Gold Plating	
0.50mm Pitch Easy-On FFC/FPC Connector, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 40 Circuits, Gold (Au) Contact Plating	<u>512964094</u>

This document was generated on Sep 16, 2025