


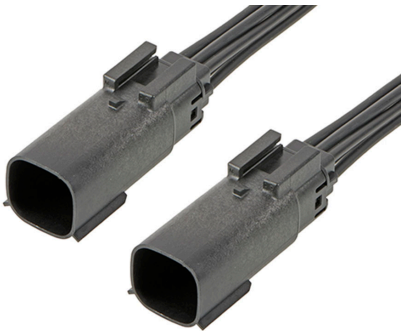

**Part Number :** [2162871062](#)  
**Product Description :** MX150 Male-to-MX150 Male Off-the-Shelf (OTS) Cable Assembly, Dual Row, 300.00mm Length, Tin (Sn) Plating, 6 Circuits, Black  
**Series Number :** 216287  
**Status :** Active  
**Product Category :** Power and Signal Cable Assemblies



## Documents & Resources

### Drawings


[Drawing 2162871062\\_sd.pdf](#)  
[Packaging Design Drawing 2162801021-001.pdf](#)

### 3D Models and Design Files

[3D Model 2162871062\\_stp.zip](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

### [Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

### [Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration

- IEC-62474  
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	Power and Signal Cable Assemblies
Series	216287
Description	MX150 Male-to-MX150 Male Off-the-Shelf (OTS) Cable Assembly, Dual Row, 300.00mm Length, Tin (Sn) Plating, 6 Circuits, Black
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	MX150-to-MX150
Product Family	MX150 Sealed and Unsealed Connector System
Product Name	MX150
Type	Discrete Wire Assembly, Sealed Assembly
UPC	193264714698

#### Electrical

Current - Maximum per Contact	22.0A
Voltage - Maximum	14V DC

#### Physical

Cable Length	300.00mm
Circuits (Loaded)	6
Circuits (maximum)	6
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin

Material - Resin	SPS/Nylon
Net Weight	628.800/g
Number of Rows	2
Overmolded	No
Packaging Type	Bag
Pitch - Mating Interface	3.50mm
Single Ended	No
Termination Interface Style	Crimp or Compression
Wire/Cable Type	TXL Stranded
Wire Insulation Diameter	2.70mm max.
Wire Size (AWG)	14

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
MX150 Mat-Sealed Dual Row Female Connector Assemblies	<u>33472</u>

---

This document was generated on Dec 11, 2023