 




toggle shown in pos. a

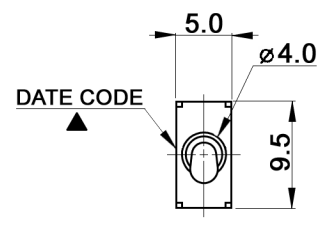

P.C. MOUNTING

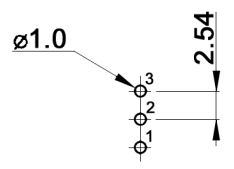

CONTACT ARRANGEMENT

code for x	function	toggle in pos. a	toggle in pos. c
D	On-On	2-3	1-2
F	On-Mom	2-3	1-2

code for x	function	toggle in pos. a	toggle in pos. b	toggle in pos. c
E	On-Off-On	2-3	open	1-2
G	Mom-Off-Mom			
H	On-Off-Mom			

Specifications:

Contact rating:	max.: 0.4VA, 48V AC or DC, 50mA min.: 1µA, 20mV AC or DC
Contact resistance:	50mOhm max. at 2-4V DC, 100mA
Insulation resistance:	1000MOhm min.
Dielectric strength:	500V RMS
Operating temperature:	-20°C to +85°C
Electrical life:	40 000 make-and-break cycles
Soldering conditions:	wave-soldering: 260 +/-5°C, 5 +/-1sec.
Protection:	IP67
Material:	Actuator: brass, chrome plated Bushing / housing: steel Case: glass filled PBT (UL94V-0) Contact / terminals: phosphor bronze, gold plated over nickel barrier



Tolerances: 0.00: ±0.25mm 0.0: ±0.40mm		Date 03/14	Name dr	ATE 1 x	
				knitter-switch	30 30 52
Modifications	Date	Name			Page 1/1