
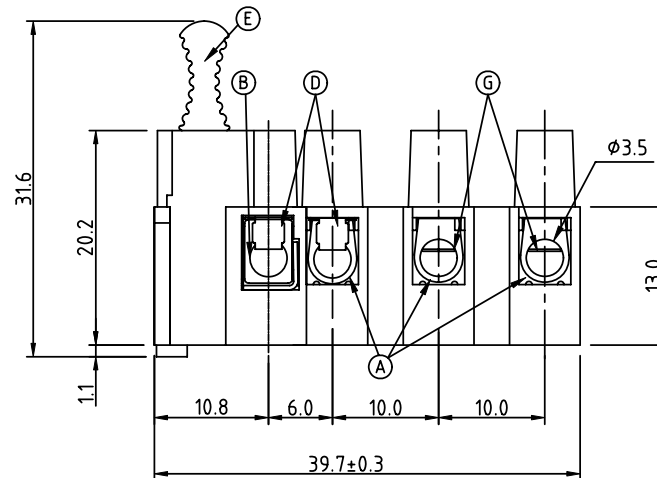
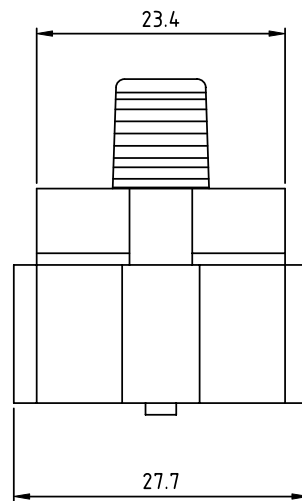


PRODUCT NUMBER	PITCH
TM041xxx00J0G	N/A

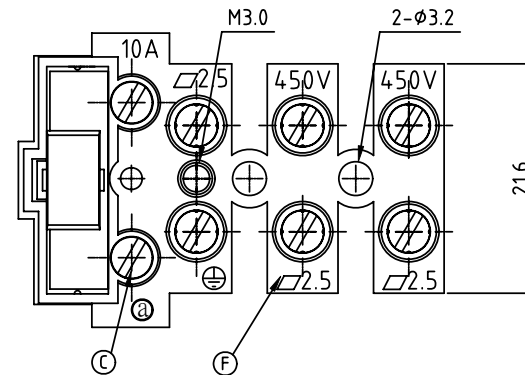

Material


- ④Terminal body(metal housing of double): Brass(CuZn),Ni plated
- ⑤Terminal body(metal housing of single): Brass(CuZn),Ni plated
- ⑥Terminal screw: Steel Zinc plating "--" slot type
- ⑦Wire guard(short): Steeless steel
- ⑧Fuse Holder: Thermoplastic (UL94V-0)
- ⑨Insulator (housing): Thermoplastic (UL94V-0)
- ⑩Wire guard(Long): Steeless steel

Electrical cULus VDE

- Voltage rating: 400VAC / 450VAC
- Current rating: 10A / 24A²
- Wire range: 0.34~2.5mm
- Solid wire(AWG): 14-22
- Stranded wire(AWG): 14-22
- Torque(Lb-In): 3.5 / 0.5 Nm
- Screw: M3
- Wire strip length: 7-8mm
- Withstanding Voltage: 1.8KV / 2.5KV
- Operating temperature: -40°C to +115°C
- Safety Approval:  

PART NO.: TM 04 1xxx 00J0 G

Body Color	Fuse Holder Color	Earth screw	RoHS compliant
8 Dark Grey	0 Black	0 W/O Earth screw	(lead<4%)
9 White		1 W/Earth screw (M3×14)	In copper Alloy
		2 W/Earth screw (M3×18)	

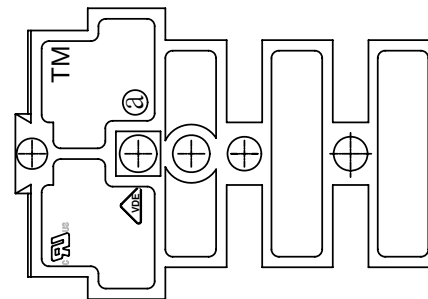[illegible]