
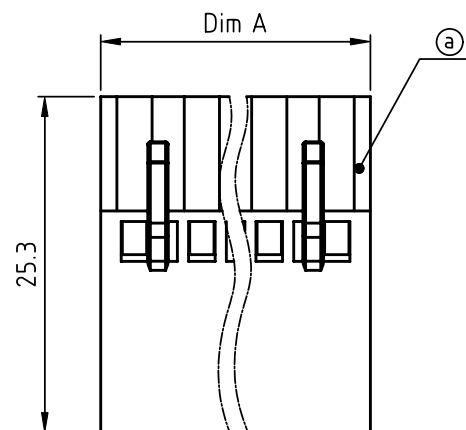
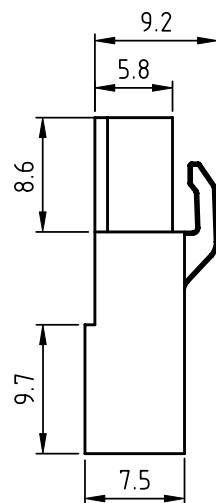
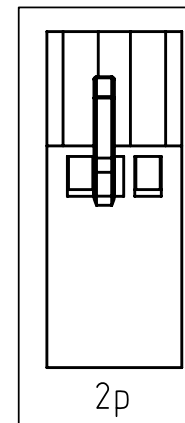


PRODUCT NUMBER	PITCH
Klxx50x000J0G	5.08 mm

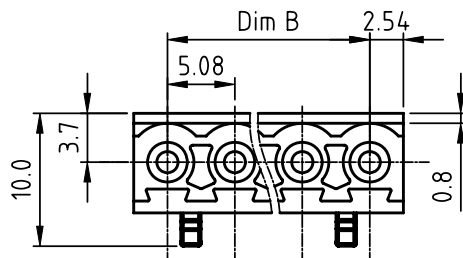

Material:

- Item@Terminal housing:Thermoplastic (UL94 V-0)

Electrical cULus

- Voltage rating: 300V
- Current rating: 10A
- Wire range: 0.5-1.0mm²/1.5-2.5mm²
- Withstanding Voltage: 1.6KV
- Corresponding female crimp contacts:A0 5.08 series

PART NO.: Kl xx 50 x 0 00J0 G

N = Number of poles
 Dim A=Nx5.08
 Dim B=(N-1)x5.08

Poles	Dim A	Dim B
2-6p	±0.20	±0.20
7-12p	±0.25	±0.25
13-16p	±0.30	±0.30
17-24p	±0.40	±0.35

Solid block	No. of poles	Color	RoHS compliant
0	2	Black (RAL9005)	(lead<4%)
02	2 poles	Red (RAL3001/D)	In copper Alloy
03	3 poles	Orange(RAL2011/P)	
...	...	4 Yellow(RAL1018/A)	
24	24 poles	5 Green(RAL6018/T)	
		6 Blue (RAL5015/A)	
		8 Grey(RAL7035/D)	
		9 White(RAL1102)	
		C Green(RAL6018/U)	

mat'l. code				surface	tolerance	projection	product family		
ltr	ecn	no	dr	date	ASME Y14.5 ✓	ASME Y14.5	TERMINAL BLOCK		
					tolerances unless otherwise specified		title		
					angles	X.±0.5	TERMINAL BLOCK		
					φ	X.X±0.3	PLUGGABLE PLUG,CRIMP CONNECTION		
					X'±1"	X.XX±0.1	scale		
					dr	EVIN ZHONG 050414	dwg no		
					enrg	EVIN ZHONG 050414	sheet 1 of 1		
					chr	HANKE FENG 050414	Klxx50x000J0G		
					appd	SHI JUN 050414	type		
							CUSTOMER Drawing		
sheet index	revision	A							
	sheet	1							