

USB MINI-B BREAKOUT BOARD

SKU: ICB00115




Description

This breakout board was designed to be a DIP adapter for a USB Mini-B connector. It makes accessing all 5 USB pins easy! You can be sure you're connected by the green power LED already built into this board.

Technical Details

Footprint Dimensions	
Body (mm):	n/a
Pitch (mm):	n/a
Thermal Pad (mm):	n/a
Breakout Board Dimensions	
Board Dimensions (mil):	640 x 520
Board Thickness (mil):	62
Through-Hole Spacing (mil):	100 mil (X-axis)
	n/a (Y-axis)
Breakout Board Specifications	
Board Layers:	2
Finish:	Immersion Gold
Copper:	1 oz
Traces (mil)	10
Trace Lengths (mil):	<200
Pin/Through-Hole Count:	5

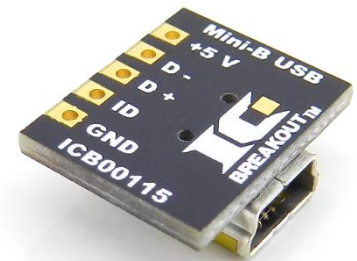


What's Included?

Parts Installed on Board:	USB Mini-B Connector, Green LED, 1.2K resistor
Parts Included (but not installed):	5 PIN Break Away Header (Straight)

Additional Features


- Easily identifiable PIN 1 indicator and PIN numbers
- Extended through-hole pads make for an easy connection point for surface mount parts
- Breadboard friendly pin spacing
- All boards have been E-tested for failures and are RoHS compliant

 Scale Image



1:1 SCALE

Dimensions

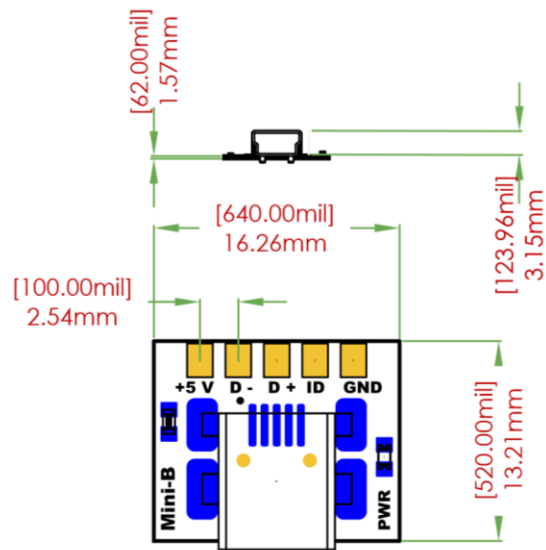

**BREAKOUT BOARD
DIMENSIONS**