


## Protect It! 3-Outlet Travel-Size Surge Protector - 5-15R Outlets, 2 USB Ports, 5-15P Input, 1050 Joules, Black

MODEL NUMBER: TRAVELER3USB

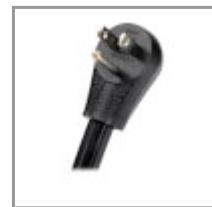

Protects your laptop and other electronics against dangerous power surges, spikes and line noise in a hotel or conference room.

### Features

#### 3-Outlet Surge Protector with USB Charging Safeguards Your Sensitive Electronics

Ideal for use in a hotel, airport, conference room or anywhere else you use your laptop, this Protect It!® surge protector features a surge protection rating of 1050 joules to defend your valuable electronic components against power surges and spikes. The 18-inch (45.7-centimeter) AC power cord with right-angle NEMA 5-15P plug connects to a wall outlet and conveniently wraps around the unit for easy storage when not in use.

#### NEMA 5-15R Outlets Accept a Wide Range of Electronic Devices

Plug your laptop, printer, external hard drives and other portable electronics into three NEMA 5-15R outlets to protect them against dangerous surges, spikes and line noise. One outlet is set apart to accommodate a bulky transformer without blocking the other outlets.

#### Premium Protection from EMI/RFI Line Noise Helps Your Equipment Perform Better

This surge protector filters out disruptive EMI (electromagnetic interference) and RFI (radio frequency interference) line noise that can disturb your electronics and inflict hardware damage or data loss. This EMI/RFI filtering also helps your connected components perform better and last longer.

#### USB Charger Keeps Mobile Devices Ready for Use

Two USB-A ports are available for charging your smartphone, tablet, MP3 player or other USB mobile devices. They share 2.1A for charging multiple devices at the same time.

#### Includes the Latest Safety Features to Maintain Your Equipment's Well-Being

A green LED confirms at a glance that your equipment is protected. Automatic shutoff permanently cuts power to outlets if the protection circuit is incapacitated, preventing equipment damage and indicating replacement is required.

### Highlights

- 3 NEMA 5-15R outlets distribute AC power to connected equipment
- 1050 joules protect your valuable electronics against dangerous surges and spikes
- Portable housing with concealable 18 in. power cord easy to carry in laptop bag
- USB-A ports share 2.1A for fast charging of phones and other mobile devices
- Easy-to-see green LED lets you know at a glance that your equipment is protected

### Package Includes

- TRAVELER3USB 3-Outlet Travel-Size Surge Protector, Black
- Owner's manual

## Specifications

### OVERVIEW



Powering Business Worldwide

TRIPP LITE  
SERIES

UPC Code	037332149626
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
<b>INPUT</b>	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V (110-125V)
Input Cord Gauge (AWG)	14
Voltage Compatibility (VAC)	120
Maximum Surge Amps	36000
Input Plug Type	NEMA 5-15P
Input Cord Details	SJT 3/C
Input Cord Length (ft.)	1.5
Right-Angle Plug	Yes
Input Cord Length (m)	0.46
Integrated Cord Clip	No
<b>OUTPUT</b>	
Output Capacity (Watts)	1800
Frequency Compatibility	60 Hz
Output (Watts)	1800
Output Receptacles	(3) 5-15R
Transformer Accommodation	(2) Yes
Output Amp Capacity	15
Right-Angle Outlets	No
<b>CONNECTIONS</b>	
Number of Ports	2
<b>USER INTERFACE, ALERTS &amp; CONTROLS</b>	
Diagnostic LED(s)	Yes
Diagnostic LED Details	Built-in LED confirm suppressor "protection present" (green) status
<b>CHARGING</b>	
Number of Charging Ports	2
Total Charging Watts	10.5
Charging Method	USB



Powering Business Worldwide

TRIPP LITE  
SERIES

Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 2.1A
Overcharge Protection	No
<b>SURGE / NOISE SUPPRESSION</b>	
AC Suppression Joule Rating	1050
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression 400, 400, 400
Automatic Shut-Off	Yes
<b>DATALINE SURGE SUPPRESSION</b>	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
<b>PHYSICAL</b>	
Material of Construction	Plastic
Power Cord Color	Black
Housing Color	Black
Mounting Holes or Slots	No
Receptacle Color	Black
Shipping Dimensions (hwd / in.)	7.70 x 2.50 x 3.40
Shipping Dimensions (hwd / cm)	19.56 x 6.35 x 8.64
Shipping Weight (lbs.)	0.70
Shipping Weight (kg)	0.32
Unit Dimensions (hwd / in.)	5.700 x 2.960 x 1.400
Unit Dimensions (hwd / cm)	14.48 x 7.52 x 3.56
Unit Weight (lbs.)	.62
Unit Weight (kg)	0.28
<b>FEATURES &amp; SPECIFICATIONS</b>	
Rotatable Outlets	No
Antimicrobial	No
GaN Technology	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	CAN/CSA-C22.2 No. 269.3 (Canada); CAN/CSA-C22.2 No. 308 (Canada); cUL Listed; UL 1449; UL 1363; UL Listed
Product Compliance	RoHS



Powering Business Worldwide

TRIPP LITE  
SERIES

#### WARRANTY & SUPPORT

Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$25,000 <a class="insuranceLink" href="//tripplite.eaton.com/support/insurance-policy">Ultimate Lifetime Insurance</a>

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.