

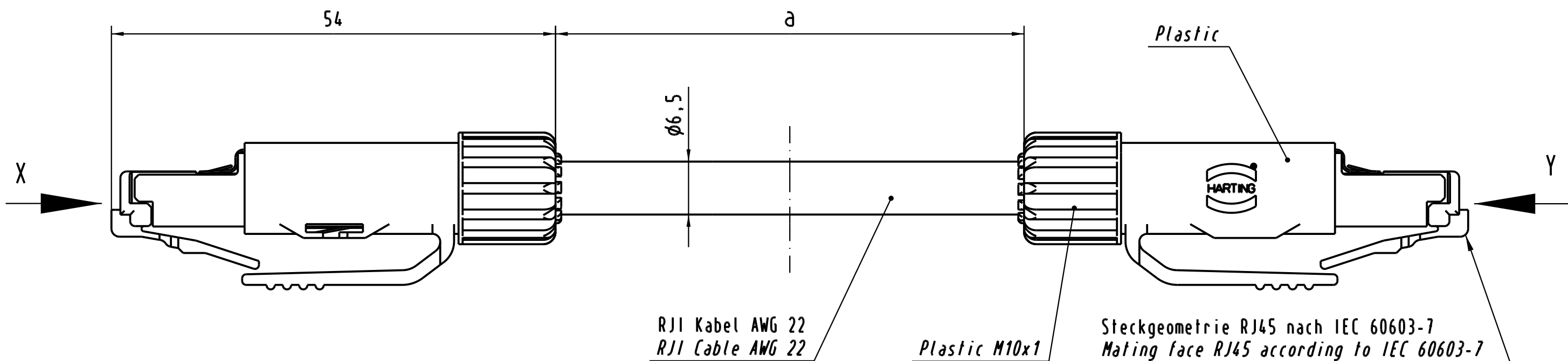
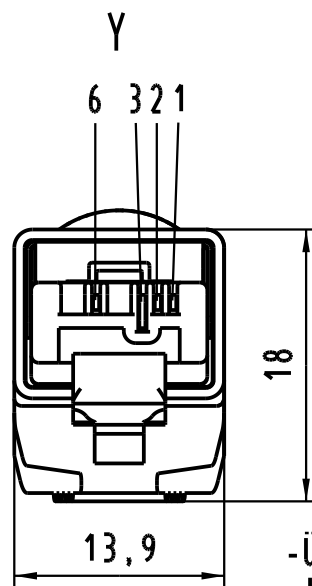


Belegungsplan
Loading-Plan

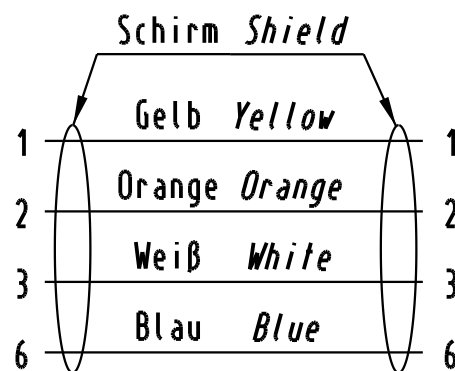

- Übertragungseigenschaften nach ISO/IEC 11801:2002: Class D.
- Schutzart: IP20
- Temperaturbereich: -40°C ... +70°C
- Transmission properties in accordance with ISO/IEC 11801:2002: Class D.
- Protection level: IP20
- Temperature range: -40°C ... +70°C

AWG 22/7 schleppfähig/trailing	09 45 751 1183	100 m
AWG 22/7 schleppfähig/trailing	09 45 751 1178	50 m
AWG 22/7 schleppfähig/trailing	09 45 751 1175	20 m
AWG 22/7 schleppfähig/trailing	09 45 751 1173	10 m
AWG 22/7 schleppfähig/trailing	09 45 751 1168	5 m
AWG 22/7 schleppfähig/trailing	09 45 751 1166	3 m
AWG 22/7 schleppfähig/trailing	09 45 751 1164	1,5 m
AWG 22/7 schleppfähig/trailing	09 45 751 1163	1 m
AWG 22/1 massiv/solid	09 45 751 1161	100 m
AWG 22/1 massiv/solid	09 45 751 1156	50 m
AWG 22/1 massiv/solid	09 45 751 1153	20 m
AWG 22/1 massiv/solid	09 45 751 1151	10 m
AWG 22/1 massiv/solid	09 45 751 1127	5 m
AWG 22/1 massiv/solid	09 45 751 1125	3 m
AWG 22/1 massiv/solid	09 45 751 1123	1,5 m
AWG 22/7 flexibel/stranded	09 45 751 0061	100 m
AWG 22/7 flexibel/stranded	09 45 751 0056	50 m
AWG 22/7 flexibel/stranded	09 45 751 0053	20 m
AWG 22/7 flexibel/stranded	09 45 751 0051	10 m
AWG 22/7 flexibel/stranded	09 45 751 0027	5 m
AWG 22/7 flexibel/stranded	09 45 751 0025	3 m
AWG 22/7 flexibel/stranded	09 45 751 0023	1,5 m
massiv / flexibel solid / stranded	Bestell-Nr. Part-No.	Maß a Dim. a

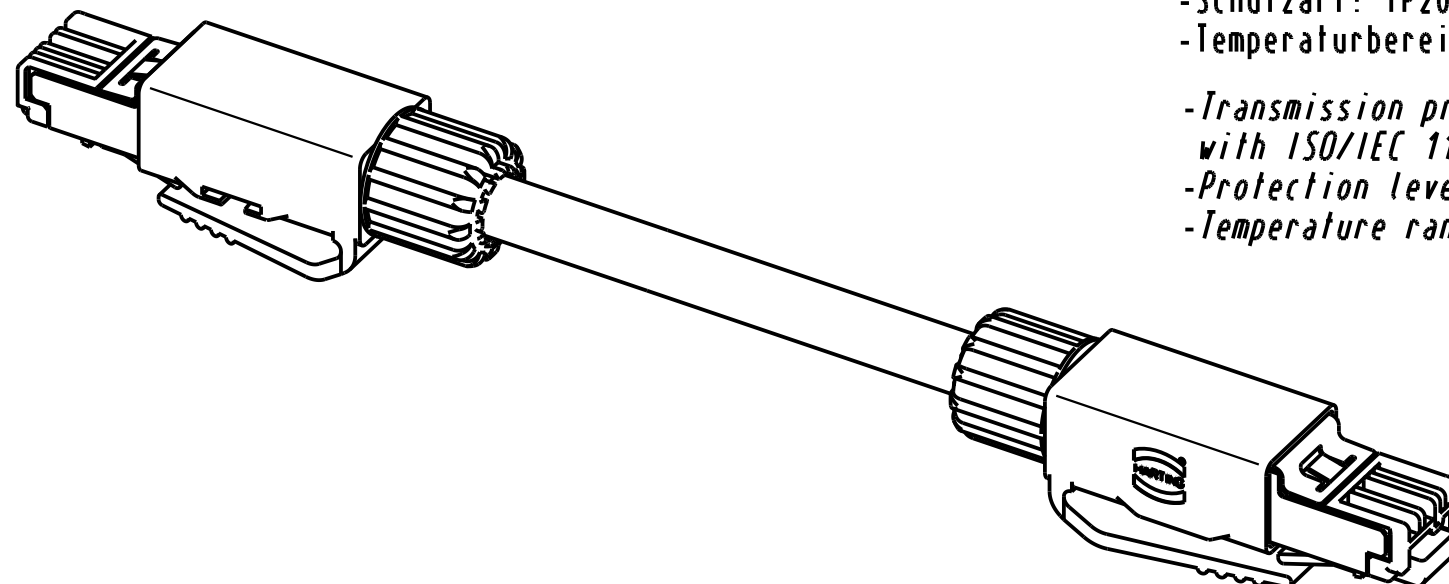

All Dimensions in mm Original Size DIN A 3			Techn. Character.			Nicht tolerierte Maß/Free size Tolerances	
Mod.	Dat.	Name		Dat.	Name	Maßstab/Scale	
32220	22.10.04	Wie	Detail.	11.06.03	Wae	2:1	RJ45 Kabel 4xAWG 22 IP20 RJ45 Cable 4xAWG 22 IP20 2x RJ45 Plastic
32089	21.06.04	Wie	Insp.	11.06.03	VSo		
31017	02.12.03	Wae	Stand.				
31014	23.09.03	Wae					
31013							
HARTING Electronics GmbH & Co. KG D-32339 ESPELKAMP			HARTING				TB 09 45 751 1123
						Sub.	Blatt/ page