


Frame Type Plug-In Unit Front Panel, Unshielded, 6 U, 14 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

CATALOG NUMBER

34812-614

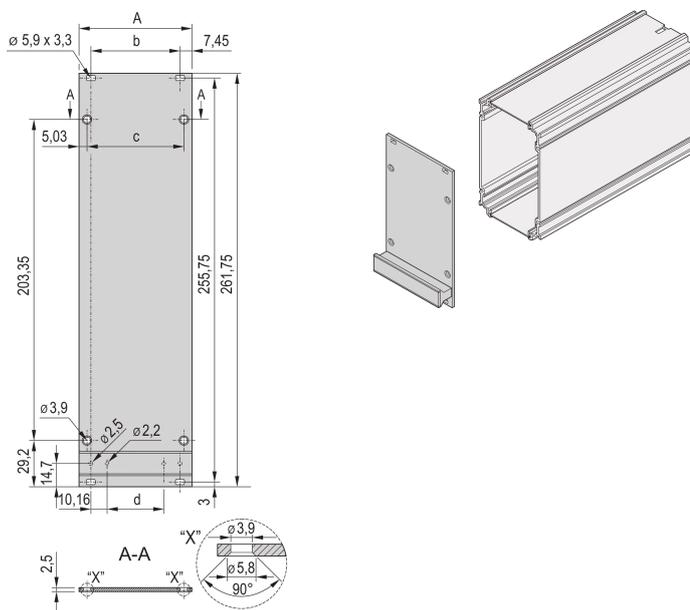

Front Panel for frame type plug-in unit, shieldable.

CERTIFICATIONS



FEATURES

Al, 2.5 mm, front anodized, rear anodized, cut edges blank

Front Panel for frame type plug-in units PRO

PRODUCT ATTRIBUTES

Product Type: Front Panel

Accessory Type: Front panel

Material: Aluminum

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 6U

Rack Width: 14HP

Package Quantity: 1


Finish: Anodized

ADDITIONAL PRODUCT DETAILS

Mounting kit to fix front Panel to plug-in unit, handle to bolt on, clip and screw with plastic sleeve for mounting plug-in unit in subrack or case are included in the item 'Mounting kit for five plug-in units', part number 24812-100. The handle is available in 2 colors (grey or black). Individual parts 100 pieces. Screw for fixing front Panel to plug-in unit, part no. 24812-501. Screw for mounting handle, part no. 24560-179 Clip - mounting aid for handle, part no. 21101-239. Screw for sleeve, threaded insert front inserted into horizontal rail, part no. 21100-748. Screw for sleeve, threaded insert rear inserted into horizontal rail, part no. 21101-101. Sleeve 21100-660, 21100-661, 21100 - 662, 21100-886, 21100-146.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

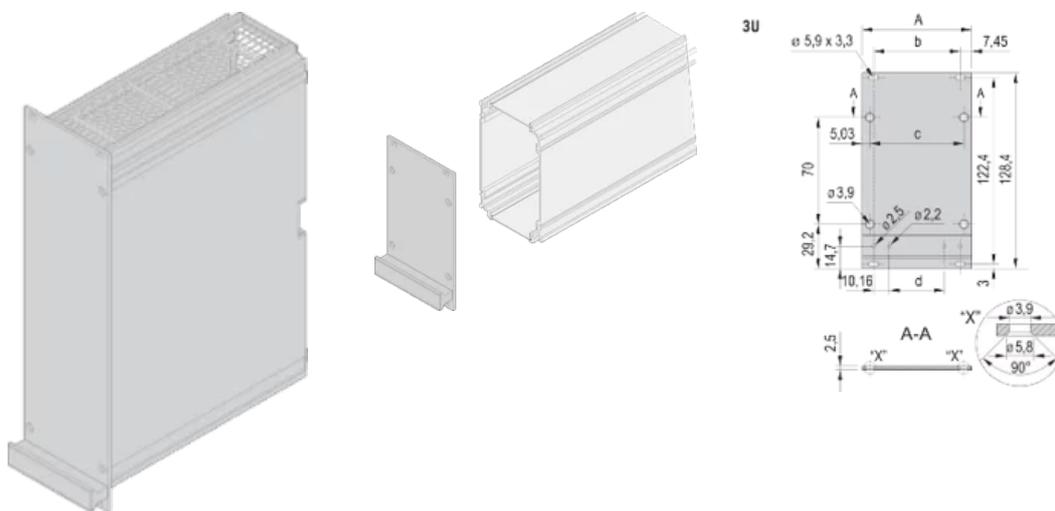

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE