


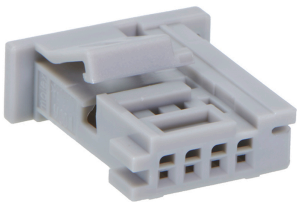

Part Number : [2058272042](#)
Product Description : ConnTAK50 Tang
Receptacle, Single Row, 4 Circuits, Key B,
Natural
Series Number : 205827
Status : Active
Product Category : Connector Housings



Documents & Resources

Drawings
[2058272042_sd.pdf](#)
[PK-31301-538-001.pdf](#)

3D Models and Design Files
[2058272042_stp.zip](#)

Specifications
[2046310000-AS-000.pdf](#)
[2046310000-PS-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Not Relevant
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	205827
Description	ConnTAK50 Tang Receptacle, Single Row, 4 Circuits, Key B, Natural
Application	Automotive, Power, Signal, Wire-to-Board
Product Name	ConnTAK50
UPC	193264109104

Physical

Circuits (maximum)	4
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	0.586/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.80mm
Pitch - Termination Interface	1.80mm
Polarization	B
Polarized to Mating Part	Yes
Stackable	No

Temperature Range - Operating	-40° to +100°C USCAR Class T2, -40° to +105°C LV-214
-------------------------------	--

Mates With / Use With

Mates with Part(s)

Description	Part Number
ConnTAK50 Right-Angle, Single Row, Surface Mount Headers	<u>208033</u>
ConnTAK50 Vertical, Single Row, Surface Mount Headers	<u>208035</u>

Use with Part(s)

Description	Part Number
TAK50 Receptacle Terminal, Unsealed, L-Grip, D-Wind, Left Reel Payoff	<u>2000963101</u>
TAK50 Receptacle Terminal, Unsealed, L-Grip, B-Wind, Right Reel Payoff	<u>2000963161</u>
TAK50 Receptacle Terminal, Unsealed, S-Grip, D-Wind, Left Reel Payoff	<u>2000963201</u>
TAK50 Receptacle Terminal, Unsealed, S-Grip, B-Wind, Right Reel Payoff	<u>2000963261</u>

This document was generated on Mar 08, 2025