

Search Results

- Evaluate
- FAQ's
- How to Buy
- Bill of Material
  - Favorite Products List
  - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click  to remove) Search Tips  Within Results

Text Search: 'GE192-L'

Your search criteria matched only one product, shown below

**GE192-L**

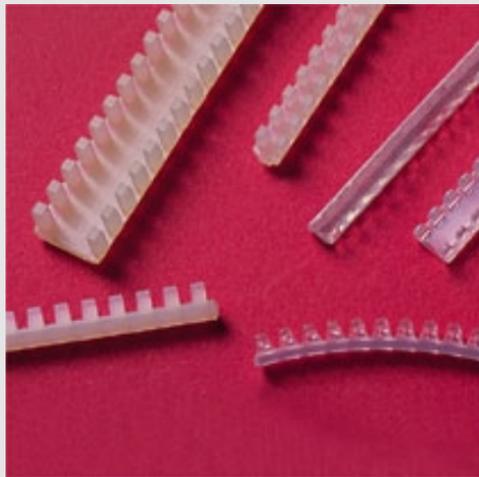

Part Number	GE192-L
RoHS Compliancy Status	Compliant
Part Description	Military Specification Nylon Grommet Edging in 12.75" strips.
Material	Nylon 6.6
Color	Natural
Military Specification	MS21266-4N
Height (In.)	.23
Height (mm)	5.8
Length (In.)	12.75
Length (mm)	323.9
Width (In.)	.33
Width (mm)	8.3
Flammability Rating	UL94 V-2
Outside Depth (In.)	.230
Outside Depth (mm)	5.8
Outside Width (In.)	.325
Outside Width (mm)	8.3
Panel Thickness Range (In.)	.128 – .192
Panel Thickness Range (mm)	3.3 – 4.9
Pricing Description	Grommet Edging, Slot Strip, Nylon, Natural
Temperature Range	-40°F to 149°F (-40°C to 65°C)
Min. Order UOM	PC
Min. Order Qty.	50
BOM Qty. (# of Pkgs.)	<input type="text" value="0"/>
Add to Favorite Product List	<input type="checkbox"/>

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.