


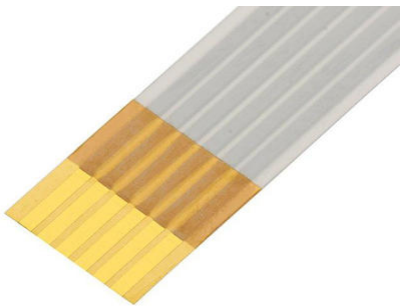

Part Number : [150670610](#)
Product Description : 1.00mm Pitch Premo-Flex Hot Bar Solder FFC Jumpers, Same Side Contacts (Type A), 152.00mm Cable Length, Tin (Sn) Plating, 10 Circuits
Series Number : 15067
Status : Active
Product Category : Flat-Flexible Cable (FFC)

Documents & Resources

Drawings
[150670610 sd.pdf](#)
Specifications
[150670001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15067
Description	1.00mm Pitch Premo-Flex Hot Bar Solder FFC Jumpers, Same Side Contacts (Type A), 152.00mm Cable Length, Tin (Sn) Plating, 10 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex Hot Bar Solder FFC Jumper
UPC	196823685903

Electrical

Current - Maximum per Contact	1.25A
Voltage - Maximum	60V AC

Physical

Cable Length	152.00mm
Circuits (Loaded)	10
Contact Layout Type	A (same side)
Design Feature	Direct to Board
Material - Plating Mating	Tin
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Temperature Range - Operating	-40° to +105°C
Termination Style	Solder
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

This document was generated on Sep 23, 2025