


Series
NSX

SIZE 1 SOCKET COAX
FOR CABLE RG400


Issue:
Mar, 18, 2011

Page
1/1


DIELECTRIC

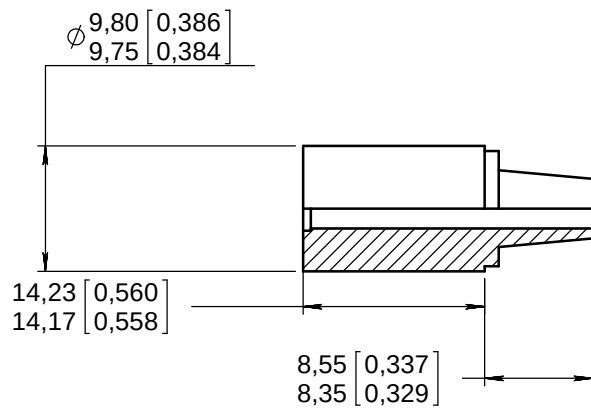


OUTER CONTACT AND RETENTION PLATE SUB ASSY

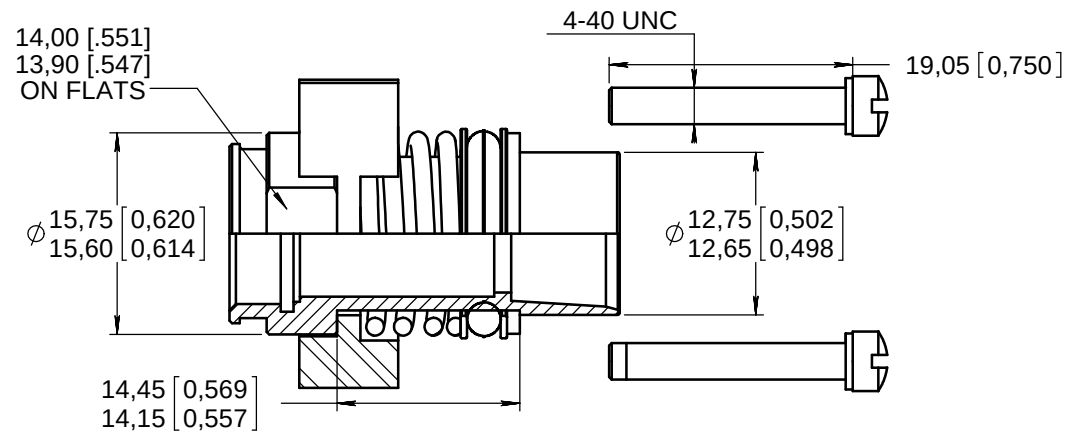


BRAID CLAMP

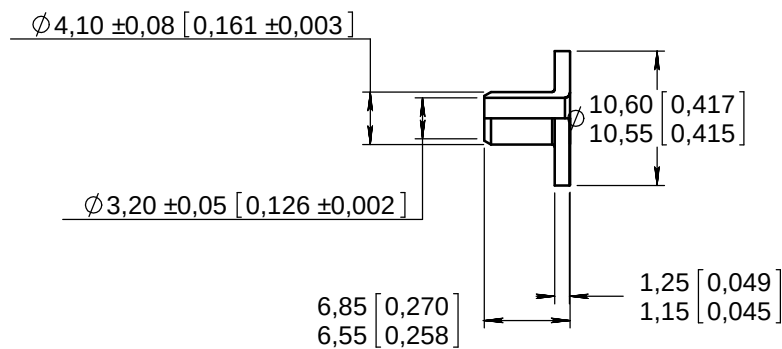


WASHER

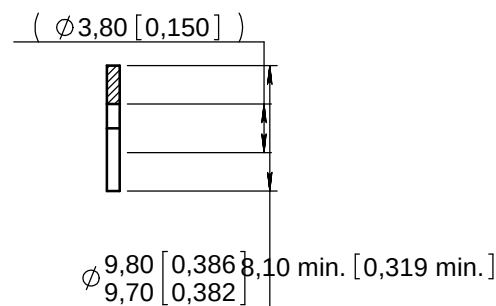


INNER CONTACT

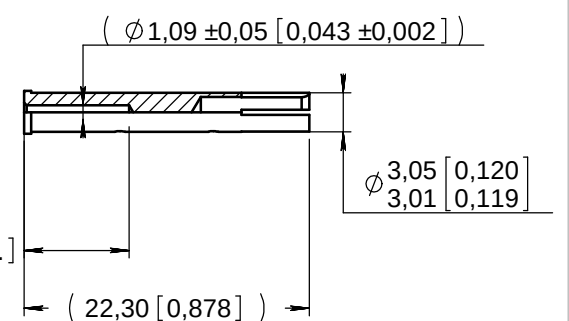


SHRINKABLE SLEEVE

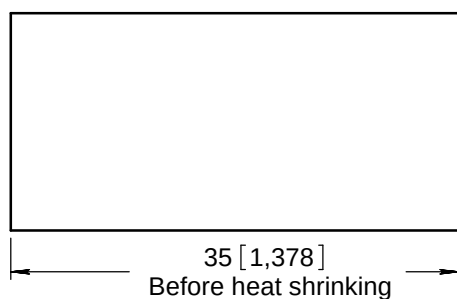

FERRULE

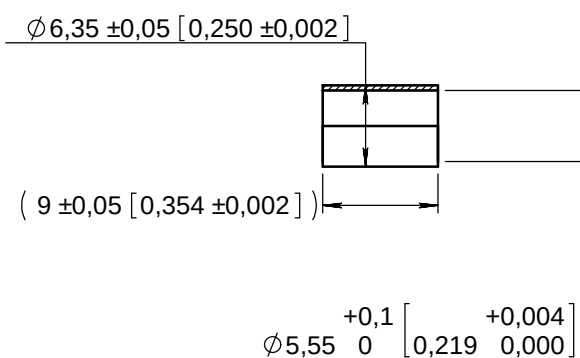

CLAMP NUT

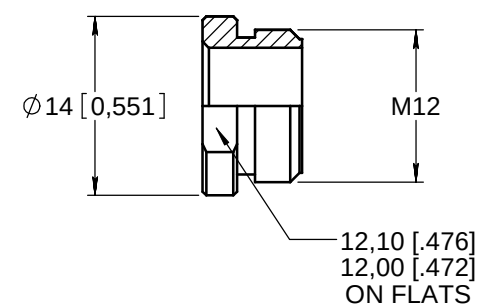

MATERIAL :

- OUTER CONTACT, CLAMP NUT, WASHER BUSHING AND BRAID CLAMP : BRASS PER ASTM B 16/B 16M OR EQUIVALENT
- CENTER CONTACT : BERYLLIUM COPPER PER ASTM-B-196
- INSULATOR : PTFE PER ASTM-B-1710 OR EQUIVALENT
- RETAINING BLOC : ALUMINIUM ALLOY PER SAE AMS-QQ-A-250
- SPRING, FLAT WASHERS, C'CLIP AND SCREWS : CORROSION RESISTANT MATERIAL
- O'RING AND GASKET : FLUOROSILICONE ELASTOMER PER SAE AMS-R-25988

FINISH :

- ALL METALIC PARTS : .00005 INCH OF GOLD PER SAE AMS-2422 OVER NICKEL PER SAE AMS-QQ-N-290 (CLASS 2)
- RETAINING BLOC : BLACK ANODIZED PER MIL-A-8625

NOTA : O'RING DELIVERED LUBRICATED

WIRING INSTRUCTION : SEE RP2798

CRIMPING TOOLS : OUTER CONTACT

- TOOL M22520\5-01 (RADIAL 282 293)
- DIE M22520\5-05 (RADIAL 282 246) HEX A


 
INNER CONTACT

- TOOL M22520\1-01 (RADIAL 282 291) SELECTOR ON 8
- POSITIONNER M22520\1-13 (RADIAL 282 997) RED TURRET

ELECTRICAL CHARACTERISTICS :

- IMPEDANCE : 50 Ohms
- VSWR 1,3 10MHz TO 5GHz
- DIELECTRIC WITHSTANDING VOLTAGE : 1500V

DIMENSIONS : mm (inch are given for information only)

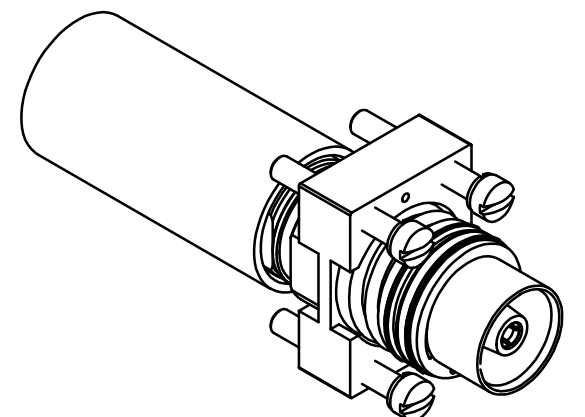

CREATION

PEN: /

NOM: HASCOET

DATE: 09 MAY 00

APPR.: .

Mar.18,11 Redraw and dimensions added

Nov.18,05 Updated material and finish

Issue

Revisions

Moutault

Valgresy

Name

Brochet

Lahoreau

Approved

620109EN

RADIAL PROPRIETARY INFORMATION

This information is given as an indication. In the continual goal to improve our products, we reserve the right to make any modifications judged necessary.

4112_9311