

Part Number : [190730168](#)


Product Description : Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Expanded Flare, Length 27.71mm, Yellow, Carton

Series Number : 19073

Status : Active

Product Category : Ring and Spade Terminals

Engineering Part Number : C-828-08X

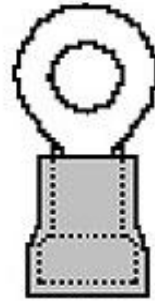

Documents and Resources

Drawings

[190730168_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19073
Description	Avikrimp Ring Tongue Terminal for 12-10 AWG Wire, Stud Size 8 (M4), Expanded Flare, Length 27.71mm, Yellow, Carton
Keyword	Ring Terminal, Ring Terminals
Product Name	Avikrimp
Style	Ring
Type	Ring Terminal, Metric Ring Terminal
UPC	800753076969

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Color - Resin	Yellow
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin

Net Weight	2.252/g
Packaging Type	Carton
Stud Size	8 (M4)
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	6.35mm max.
Wire Size (AWG)	10, 12
Wire Size mm ²	4.00-6.00

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 22-10 AWG and 6.0-0.5mm ² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>640010100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050100</u>
ServiceGrade Hand Crimp Tool for Field Repair only, for production use our PremiumGrade Tool	<u>640160036</u>

This document was generated on Jun 01, 2026