


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/4/12

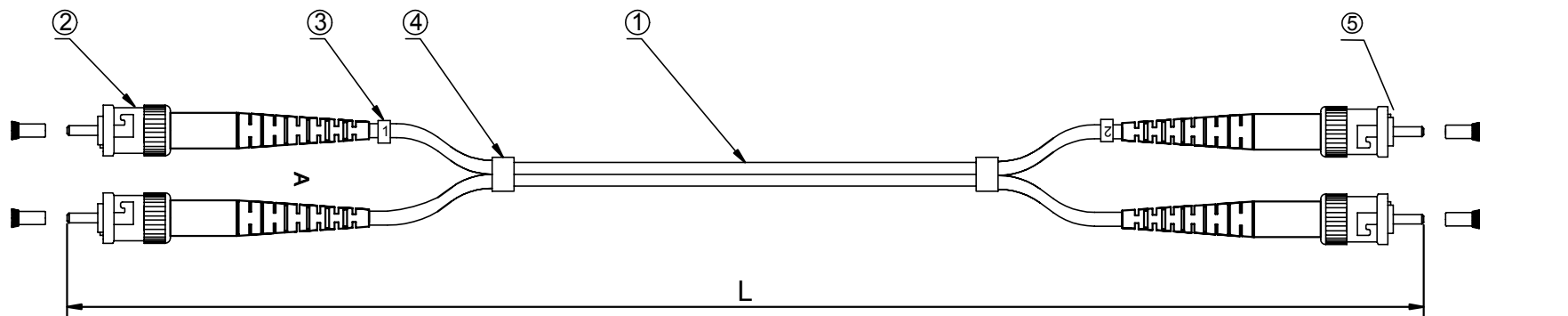

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
933M-2-1-00100	671-443-A	1000±100	Orange
933M-2-1-00200	671-443-B	2000±100	Orange
933M-2-1-00300	671-443-C	3000±100	Orange
933M-2-1-00500	671-443-D	5000±100	Orange
933M-2-1-00700	671-443-E	7000±100	Orange
933M-2-1-01000	671-443-F	10000±100	Orange
933M-2-1-01500	671-443-G	15000±100	Orange
933M-2-1-02000	671-443-H	20000±100	Orange
933M-2-1-02500	671-443-I	25000±100	Orange

NOTES:
Insertion loss < 0.3 dB

CnC Tech, LLC

Industrial Cable and Connector Technology

6	
5	Dust Cover
4	Shrinkage Tube
3	$\frac{1}{2}$ Code
2	ST MM Connector (Metal housing Red/black boot)
1	2.0mm,Duplex,MM-62.5/125, PVC, Optical Fiber Cable(Orange)
No.	Description

		TITLE		Patch Cord, ST-ST,MM-62.5/125 OM1, Duplex, PVC, orange, 2.0mm, xxM	
UNIT		P/N		DRAWN BY	
unless otherwise stated mm Tolerances XXX.XX ±0.3 ±2° XX.XX ±0.2 X:XX ±0.1		Customer P/N		CHECK BY	
SIZE A4		SCALE Free		PAGE	1/1
				APPROVAL BY	