

H0,14/10 GR SV


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

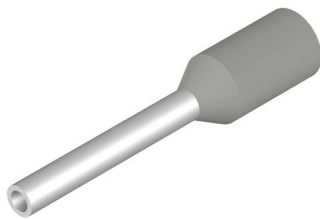

- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Version	Wire-end ferrule, Standard, 8 mm, 6 mm, grey
Order No.	9005180000
Type	H0,14/10 GR SV
GTIN (EAN)	4008190859909
Qty.	500 items
Packaging	Multipack bag

H0,14/10 GR SV

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data
Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 0.05 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, grey	Version	Standard
------------------------	--	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	0.6 mm	Contact surface length (L2)	6 mm
Collar diameter (D2)	1.5 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	10.00 mm	Wire connection cross section AWG, max.	AWG 26
Metal sleeve thickness (S1)	0.15 mm	Stripping length	8 mm
Conductor cross-section	0.14 mm ²	Colour code	Weidmueller

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

