

AMMA000404201R0MV1

Search by : [Part Number](#) [Characteristics](#) [Cross reference](#)




NEW ?

Closed Magnetic Circuit Type
Molding Processing & for Ultra High Current

Series Pdf

Product detail		
	L(mm) ±	4.06±0.25
	W(mm) ±	4.45±0.25
	T(mm) ±	2.0Max.
	Inductance(uH)	1
	Tolerance(±%)	20
	Test Frequency	100kHz,0.25V
	RDC(Ω)Max	0.037
	RDC(Ω)Typ	0.033
	Isat(A)Typ	8.5
	Irms(A)Typ	3.75
	Operating Temperature	−55℃~125℃

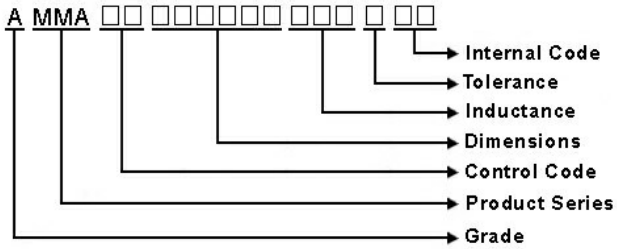

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Filter/Antennas
- RF-Wireless Power Transfer
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



[Inductor](#)



[Resistor](#)



[Powder](#)

Copyrights © 2018. Chilisin. All rights reserved.