


CL5A08UXXX

(M12 Cordset, L-Code, 5 Position, 16 AWG Unshielded, Male Straight to Free End)

MALE FACE VIEW

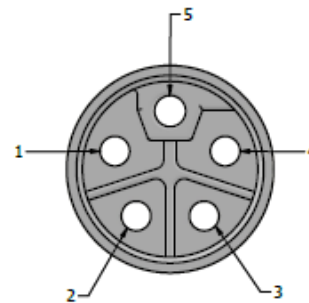

1 → BLUE
2 → GRAY
3 → BLACK
4 → BROWN
5 → GREEN/YELLOW

- Mueller's CL5A08UXXX is an M12 L coded 5-pin single ended, unshielded instrumentation cable with a straight male connector on one end and free at the other.
- Keyway – L Coding
- Utilizes a 5-conductor 16 AWG HD-PE-insulated, unshielded cable.
- Ratings:
 - Current: 16A
 - Voltage: 63V AC/DC
- Material:
 - Coupling Nuts – Nickel Plated Brass
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

Mueller Electric Company
2850 Gilchrist Rd. Bld 5A
Akron, OH 44305

www.muellerelectric.com

Toll Free: 800.955.2629
Phone: 330.780.2525
Fax: 330.780.2524