

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0500138100

Status:

Active

Description:

2.00mm Pitch Crimp Terminal, for 51005 Housing

Documents:

3D Model

Drawing (PDF)

Product Specification PS-51005-001-001 (PDF)

Packaging Specification SPK-50013-001-001 (PDF)


RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	50013
Application	Signal
Crimp Quality Equipment	Yes
Packaging Alternative	500138000 (Reel)
Product Name	N/A
UPC	800753576254
Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	47.900/mg
Packaging Type	Bag
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.90-1.15mm
Wire Size AWG	24, 26, 28
Wire Size mm²	N/A

Electrical	
Current - Maximum per Contact	2.0A
Voltage - Maximum	125V

Material Info

Reference - Drawing Numbers	
Crimp Specification	CS-50012_50013
Packaging Specification	SPK-50013-001-001
Product Specification	PS-51005-001-001
Sales Drawing	SD-50013-001

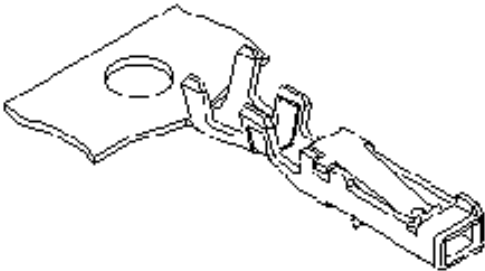

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

50013 Series

Mates With

50012

Use With

51005

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Hand Crimp Tool for 2.00mm Pitch Wire-to-Wire Crimp Terminal, 24-28 AWG	638117800
Japan	
Description	Product #

This document was generated on 09/17/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION